


205558-3 Product Details

Have a Question?

Chat with a Product Information Specialist

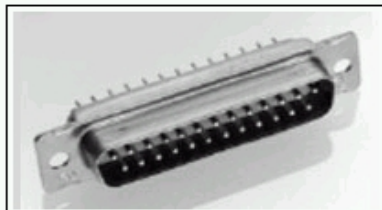

Subminiature D Pins/Sockets for MIL-C-24308 and MIL-C-39029

[Not reviewed for RoHS Compliance](#)

Product Highlights:

- Connector
- Product Series = 109
- Connector Style = Plug
- Contact Type = Pin
- Density = Standard

[View all Features](#)

205558-3
(M24308/4-7F)
TE Internal Number: 205558-3

Active

[View 3D PDF](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [AMPLIMITE, KIT,HDM-20, SERIES, PLUG, SIZE 2, 15 POSITION](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version G)
- [3D Model](#) (IGES, Version G)
- [3D Model](#) (STEP, Version G)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Insert Arrangement](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Connector
- [Product Series](#) = 109
- [Shell Size](#) = 2
- [Shell Material](#) = Steel
- [Termination Method to Wire/Cable](#) = Crimp
- [Mounting Hole Diameter \(mm \[in\]\)](#) = 3.05 [.120]

Body Related Features:

- [Number of Positions](#) = 15
- [Blindmate](#) = No
- [Non-Magnetic](#) = No
- [Rear Grommet](#) = No
- [Power/Signal/Coax Combination](#) = No
- [Shell Plating](#) = Cadmium
- [Mount Style](#) = Mounting Holes
- [Retention Clip Material](#) = Stainless Steel

Contact Related Features:

- [Contact Type](#) = Pin
- [Contact Size](#) = 20
- [Contact Style](#) = Crimp Snap-in

Housing Related Features:

- [Connector Style](#) = Plug

Configuration Related Features:

- [Density](#) = Standard

Industry Standards:

- [Government/Industry Qualification](#) = Yes
- [Government/Industry Part Number](#) = M24308/4-7F
- [RoHS/ELV Compliance](#) = Not reviewed for ELV/RoHS compliance
- [Lead Free Solder Processes](#) = Not reviewed for lead free solder process
- [NASA Qualification](#) = No

Conditions for Usage:

- [Applies To](#) = Wire

Other:

- [Brand](#) = AMP
- [Comment](#) = Size 20 contacts supplied with connectors are loose piece.; Includes insertion/extraction tool.

[BOOKMARK](#)

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat with Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:



Visit Us On:

