


1-2007394-6 Product Details

[Share](#) [Print](#) [Email](#)

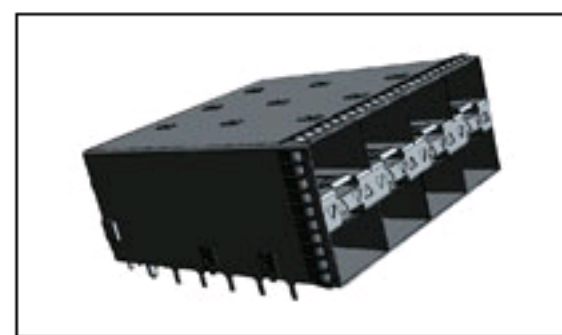

1-2007394-6

TE Internal Number: 1-2007394-6
 Active

Pluggable Connectors, Cages & Accessories

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- SFP+ Product Line
- Cage Assembly with Integrated Connector
- SFP+ Enhanced EMI Application
- Connector Style = Receptacle
- Cage Type = Stacked

[View all Features](#)

Quick Links

- ▶ Pricing & Availability
- ▶ Search for Tooling
- ▶ Product Feature Selector
- ▶ Contact Us About This Product

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Feedback

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • CAGE AND PT CONNECTOR ASSEMBLY, WITH EMI SPRINGS, PR... (PDF, English) <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • None Available <p>Product Specifications:</p> <ul style="list-style-type: none"> • SFP+ Stacked Connector and Cage Assemblies (PDF, English) <p>Application Specifications:</p> <ul style="list-style-type: none"> • Stacked Small Form-Factor Pluggable (SFP+) Connector... (PDF, English) <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Related Products:</p> <ul style="list-style-type: none"> • Tooling

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Product Line = SFP+ • Product Type = Cage Assembly with Integrated Connector <p>Mechanical Attachment:</p> <ul style="list-style-type: none"> • PCB Mount = Single Sided <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Data Signal Rate (Gb/s) = Up to 16 <p>Termination Features:</p> <ul style="list-style-type: none"> • Termination Method to PC Board = Through Hole - Press Fit <p>Dimensions:</p> <ul style="list-style-type: none"> • Tail Length (mm [in]) = 3 [0.118] • PCB Thickness, Recommended (mm [in]) = 1.50 [0.059] • Length (X-Axis) (mm [in]) = 63.50 [2.500] • Width (Z-Axis) (mm [in]) = 57.41 [2.260] • Profile Height (Y-Axis) (mm [in]) = 25.50 [1.0039] <p>Body Features:</p> <ul style="list-style-type: none"> • Integrated Light Pipes = Yes <p>Contact Features:</p> <ul style="list-style-type: none"> • Contact Plating, Mating Area, Material = Gold or Gold Flash over Palladium Nickel • Contact Base Material = Copper Alloy <p>Housing Features:</p> <ul style="list-style-type: none"> • Connector Style = Receptacle • Cage Type = Stacked • Housing Material = Liquid Crystal Polymer (LCP) • Housing Color = Black • Cage Material = Nickel Silver 	<p>Configuration Features:</p> <ul style="list-style-type: none"> • Port Configuration = 2x4 • Lightpipe = With • Lightpipe Configuration = Inner • EMI Containment = External Springs <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Not relevant for lead free process • RoHS/ELV Compliance History = Always was RoHS compliant • UL Flammability Rating = UL 94V-0 <p>Conditions for Usage:</p> <ul style="list-style-type: none"> • Applies To = Printed Circuit Board <p>Operation/Application:</p> <ul style="list-style-type: none"> • Application = SFP+ Enhanced EMI <p>Packaging Features:</p> <ul style="list-style-type: none"> • Packaging Method = Box/Carton <p>Other:</p> <ul style="list-style-type: none"> • Brand = TE Connectivity

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

