


Search bar: What can we help you find?

Home > Products > Wire & Cable > Product Feature Selector > Product Details

167019-6 Product Details

Share | Print | Email

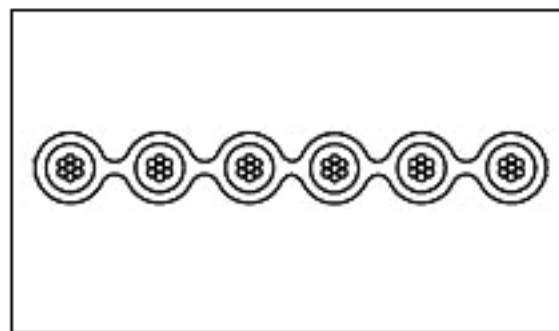

167019-6

TE Internal Number: 167019-6
Active

Flat Ribbon Cable

Converted to EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- 1.27 mm Centerline
- Wire Size - Details = 28 (7/36TC)
- Number of Conductors = 6
- Ribbon Cable Outside Conductor Spacing = 6.35 mm
- Width = 7.28 mm

[View all Features](#)

[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

Quick Links

- ▶ Pricing & Availability
- ▶ Search for Tooling
- ▶ Product Feature Selector
- ▶ Contact Us About This Product

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Line Drawing](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Ribbon Cable Outside Conductor Spacing \(mm \[in\]\) = 6.35 \[0.250\]](#)
- Color = Gray

Electrical Characteristics:

- Voltage Rating (VAC) = 300

Dimensions:

- Width (mm [in]) = 7.28 [0.287]
- Height (mm [in]) = 0.93 [0.037]

Body Features:

- [Insulation Material](#) = PVC

Housing Features:

- Centerline (mm [in]) = 1.27 [0.050]

Configuration Features:

- Number of Conductors = 6

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Converted to comply with RoHS directive

Conditions for Usage:

- [Wire Size - Details](#) = 28 (7/36TC)
- Temperature Range (°C) = -20 - +105

Other:

- Brand = AMP

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

