


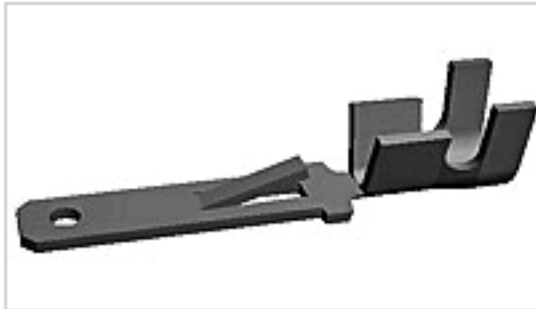

## 2-293041-1 Product Details

[Share](#) | [Print](#) | [Email](#)


### Multiple Circuit Housings with Tabs & Receptacles

FF TAB CONTACT 6.3 SERIES (STRIP FORM)

**2-293041-1**

TE Internal Number: 2-293041-1

Active

[View 3D PDF](#)

**Product Highlights** [View All](#)

- Contact
- Contact Type = Tab
- Mating Area Interface Dimensions = 6.35 x 0.80 mm
- Wire Range = 0.35-1.00<sup>2</sup> [28-17] mm [AWG]
- Insulation Diameter = 2.03 [.080] Max. mm [in]

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

**Please Note:**

Use the Product Drawing for all design activity

Product Type Features	
Product Type <sup>?</sup>	Contact
Wire/Cable Type <sup>?</sup>	Regular Wire
Finish <sup>?</sup>	None
Insertion Force <sup>?</sup>	Normal
Insulation Support <sup>?</sup>	With
FASTON	Yes
Termination Features	
Crimp Type <sup>?</sup>	F-Crimp
Dimensions	
Mating Area Interface Dimensions (mm [in]) <sup>?</sup>	6.35 x 0.80 [.250 x .031]
Insulation Diameter (mm [in]) <sup>?</sup>	2.03 [.080] Max.
Body Features	
Wire Range (mm [AWG]) <sup>?</sup>	0.35-1.00 <sup>2</sup> [28-17]
Material <sup>?</sup>	Brass

Contact Features	
Contact Type	Tab
Industry Standards	
RoHS/ELV Compliance <sup>?</sup>	RoHS compliant, ELV compliant
Lead Free Solder Processes <sup>?</sup>	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant
Packaging Features	
Packaging Method <sup>?</sup>	Reel
Packaging Quantity	3,000/Reel
Other	
Line	FASTIN-FASTON .250
Brand	TE Connectivity

**Related Products**

Not quite the product you're looking for?  
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

