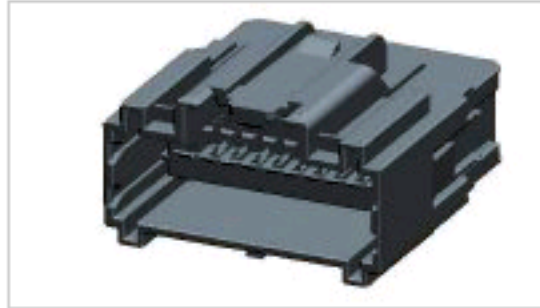


2208018-2 Product Details

[Share](#) | [Print](#) | [Email](#)


Active

0.64 mm Connector Systems

22POS,0.64 MALE GEN. Y,PIN HSG,ASSY

2208018-2

TE Internal Number: 2208018-2

Product Highlights [View All](#)

- Product Series = Generation Y 0.64 mm
- Wire-to-Wire
- Applies To Wire/Cable
- Connector
- Housing

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
Use the Product Drawing for all design activity

| Product Type Features | |
|-----------------------|----------------------|
| Product Series | Generation Y 0.64 mm |
| Product Type | Connector |
| Connector Type | Housing |
| Sealed | No |
| Integrated Management | No |

| Mechanical Attachment | |
|------------------------|------------|
| Contact Retention | With |
| Contact Retention Type | Spacer |
| Mating Retention Type | Latch(ing) |

| Body Features | |
|------------------------------|---------|
| Assembly Integration Feature | Without |
| Mating Retention | With |

| Contact Features | |
|------------------------|---------|
| Contact Type | Pin |
| Multiple Contact Types | Without |

| Housing Features | |
|-----------------------|--------------|
| Connector Style | Plug |
| Housing Material | PA66 GF35 |
| Housing Color | Natural |
| Centerline (mm [in]) | 2.54 [0.100] |
| Mating Alignment | With |
| Mating Alignment Type | Keyed |

| Configuration Features | |
|------------------------|---------|
| Number of Positions | 22 |
| Number of Rows | 2 |
| Strain Relief | Without |

| Industry Standards | |
|-----------------------------|---|
| RoHS/ELV Compliance | RoHS compliant, ELV compliant |
| Lead Free Solder Processes | Not reviewed for lead free solder process |
| RoHS/ELV Compliance History | Always was RoHS compliant |

| Identification Marking | |
|------------------------|---|
| Keying | B |

| Environmental | |
|---------------------------------|-------------------------|
| Operating Temperature (°C [°F]) | -40 - +125 [-40 - +257] |

| Conditions for Usage | |
|----------------------|------------|
| Applies To | Wire/Cable |

| Operation/Application | |
|-----------------------|--------------|
| Application Use | Wire-to-Wire |

| Packaging Features | |
|--------------------|------------|
| Packaging Method | Box/Carton |
| Packaging Quantity | 500 |

| Other | |
|-------|-----------------|
| Brand | TE Connectivity |

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

- Corporate Information**
- [About TE](#)
 - [Investors](#)
 - [News Room](#)
 - [Supplier Portal](#)
 - [Careers](#)
 - [Terms & Conditions](#)
 - [Privacy Policy](#)
 - [Global Accessibility Statement](#)

- Quick Links**
- [Distributor Inventory](#)
 - [Product Cross Reference](#)
 - [Documents & Drawings](#)
 - [Product Compliance Support Center](#)
 - [Site Map](#)

- Customer Support**
- [Email or Chat With Us](#)
 - [Find a Phone Number](#)
 - [Knowledge Base](#)
 - [Manage Your Account](#)

Keep Me Informed