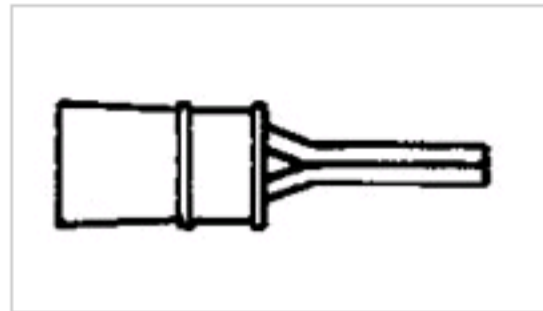


342126-1 Product Details

[Share](#) | [Print](#) | [Email](#)


✓ Active

Miscellaneous Terminals

22-16 F.E.P.G. WIRE PIN

342126-1

TE Internal Number: 342126-1

Product Highlights [View All](#)

- Insulation Support
- Wire Range = 0.30-1.42² [22-16] mm [AWG]
- Not For Use With Double Wire
- Length = 20.57 mm
- Color = Red

- [Pricing & Availability](#)
- [Request Sample](#)
- [Add to My Part List](#)
- [Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:
Use the Product Drawing for all design activity

Product Type Features	
Insulation Support	Insulation Support
Color	Red
Finish	Tin
Bulb	Without
Insulation	Yes
Wire/Cable Type	Regular Wire
Dimensions	
Length (mm [in])	20.57 [0.810]
Insulation Diameter (mm [in])	3.56 [.140] Max.
Body Features	
Wire Range (mm [AWG])	0.30-1.42 ² [22-16]
Double Wire	No
Material	Copper
Body Style	Straight
Insulation Sleeve Material	PVC

Configuration Features	
Diode	Without
Industry Standards	
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not reviewed for lead free solder process
RoHS/ELV Compliance History	Always was RoHS compliant
Packaging Features	
Packaging Method	Loose Piece
Other	
Brand	AMP
Proprietary Name	PLASTI-GRIP

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

- Corporate Information**
- [About TE](#)
 - [Investors](#)
 - [News Room](#)
 - [Supplier Portal](#)
 - [Careers](#)
 - [Terms & Conditions](#)
 - [Privacy Policy](#)
 - [Global Accessibility Statement](#)

- Quick Links**
- [Distributor Inventory](#)
 - [Product Cross Reference](#)
 - [Documents & Drawings](#)
 - [Product Compliance Support Center](#)
 - [Site Map](#)

- Customer Support**
- [Email or Chat With Us](#)
 - [Find a Phone Number](#)
 - [Knowledge Base](#)
 - [Manage Your Account](#)

Keep Me Informed