


1-5164711-2 Product Details

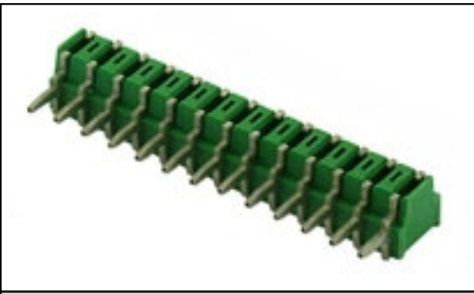

1-5164711-2

✓ [Active](#)

2.5mm & 5mm Miniature Interconnection System - IDC (Mini-Match)

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Receptacle
- Number of Positions = 12
- 2.50 mm Centerline
- Terminate To Printed Circuit Board
- PCB Mount Angle = Right Angle

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [3-20 pos female board tp board connector assembly fo...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [PCB Layout](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Receptacle
- Number of Positions = 12
- PCB Mount Angle = Right Angle
- Color = Green
- Comment = Board-to-Board applications

Body Related Features:

- Centerline (mm [in]) = 2.50 [0.098]
- Material Flammability Rating = UL 94V-0

Contact Related Features:

- Contact Material = Brass
- Contact Mating Area Plating = Tin

Housing Related Features:

- Housing Material = Thermoplastic Polyester

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not reviewed for lead free solder process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Terminate To = Printed Circuit Board

Other:

- Brand = AMP