


1059172 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

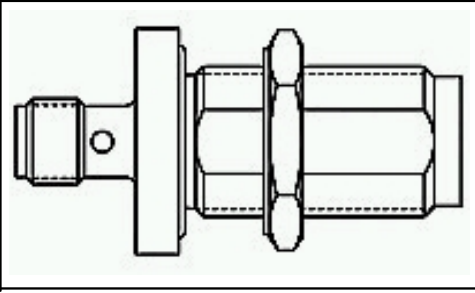

1059172 -1

[Active](#)

Between Series Adapters, RF Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Jack-Jack
- ? Adapter Type = SMA - TNC

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [OSM JACK TO OST JACK BULKHEAD FEEDTHRU ADAPTER](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? Gender = Jack -Jack
- ? Adapter Type = SMA - TNC
- ? Mount = Bulkhead Adapter
- ? Dielectric Material = TFE Fluorocarbon

Body Related Features:

- ? O-Ring Material = Fluorocarbon Rubber

Contact Related Features:

- ? Center Contact Material = Beryllium Copper
- ? Center Contact Plating = Gold

Housing Related Features:

- ? Housing Material = Stainless Steel

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- ? Brand = AMP