




+ CONNECTORS

OTHER AUTOMOTIVE CONNECTOR ACCESSORIES

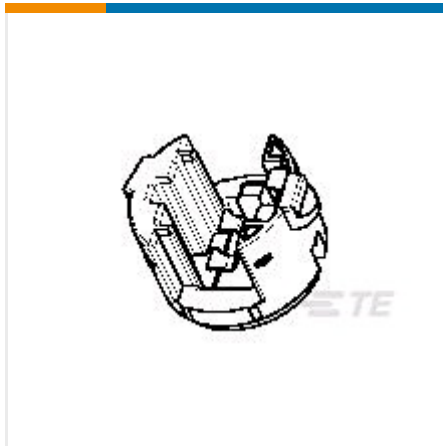

✓ Active

TE CONNECTIVITY (TE)

SQUIB 11DIA SCR ASSY 9.3MM TYP

AMP

1376766-3

TE Internal Number: 1376766-3

EU RoHS Compliant

EU ELV Compliant

Accessory Type Other

Connector System Wire-to-Wire

Material PBT

Color Orange

Operating Temperature Range -40 – 120 °C [-40 – 248 °F]

↓ **PRODUCT DRAWING**
Japanese

↓ **3D PDF**

DOCUMENTATION

Product Drawings

SQUIB 11DIA SCR ASSY 9.3mm TYPE

PDF (TIFF AVAILABLE)

Japanese

CAD Files

Customer View Model

2D_DXF.ZIP

English

3D PDF

PDF

3D

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

Product Specifications

Product Specification

SQUIB 11DIA SHORT CIRCUIT RING

PDF

Japanese

SQUIB 11DIA SHORT CIRCUIT RING

TIF

Japanese

SQUIB 11DIA Short Circuit Ring

PDF

Japanese

SQUIB 11DIA Short Circuit Ring

PDF

Japanese

Instruction Sheets

Instruction Sheet (non U.S.)

11DIA SQUIB SCR ASSY

PDF

English

11DIA SQUIB SCR ASSY

TIF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Accessory Type Other

Connector System Wire-to-Wire

Body Features

Material PBT

Color Orange

Usage Conditions

Operating Temperature Range -40 – 120 °C [-40 – 248 °F]

Industry Standards

UL Flammability Rating UL 94-HB

Packaging Features

Packaging Quantity 2000

Packaging Method Bag

Other

Serviceable Yes

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
