


1411558-2 Product Details

[Live Product Chat](#)

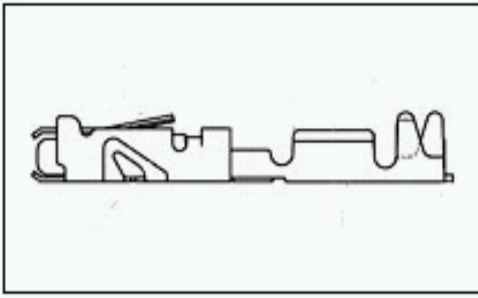

1411558-2

TE Internal Number: 1411558-2

[Active](#)

Miscellaneous Automotive

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Contact
- Contact Type = Receptacle
- Mount = Wire Crimp
- Wire Range = 0.75² [18.5] mm [AWG]
- Gold Contact Mating Area Plating Material

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#)

Documentation & Additional Information

Product Drawings:

- [Buchsenkontakt, Crimp-Version](#) (PDF, German)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Contact
- Mount = Wire Crimp

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.75² [18.5]

Contact Related Features:

- [Contact Type](#) = Receptacle
- [Contact Mating Area Plating Material](#) = Gold
- Contact Material = Copper Alloy

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- Packaging Method = Reel
- Packaging Quantity = 17,500

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)