


173636 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

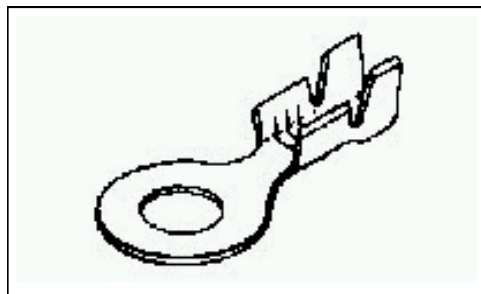

173636 -1

Active

Ring and Spade Tongue Terminals

Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- ? Terminal Shape = Ring Tongue
- ? Receptacle Style = Straight
- ? Barrel Type = Open Barrel
- ? Wire/Cable Type = Regular Wire
- ? Wire Range = 0.30 - 1.40² [22 - 16] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [RING TERMINAL](#) (PDF, Japanese)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? [Terminal, AMPLIVAR, Ring, Crimping](#) (PDF, English)
- ? [Terminal, Ring, Extruded, Crimping](#) (PDF, English)
- ? [Design Objectives, Ring Terminal](#) (PDF, Japanese)

Application Specifications:

- ? [Crimping Conditions of Ring Terminals](#) (PDF, Japanese)

Instruction Sheets:

- ? None Available

CAD Files: ([CAD Format & Compression Information](#))

- ? [2D Drawing](#) (DXF, Version O1)
- ? [3D Model](#) (IGES, Version O1)
- ? [3D Model](#) (STEP, Version O1)

[List all Documents](#)

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Terminal Shape](#) = Ring Tongue
- ? [Receptacle Style](#) = Straight
- ? [Barrel Type](#) = Open Barrel
- ? [Wire/Cable Type](#) = Regular Wire
- ? [Insulation](#) = Yes
- ? [Insulation Support](#) = Insulation Support
- ? [Insulation Diameter \(mm \[in\]\)](#) = 2.50 - 3.60 [.098 - .142]
- ? Stud Size = None
- ? [Stud Diameter \(mm \[in\]\)](#) = 4.40 [0.173]
- ? [Shape](#) = RING -008
- ? [Heavy Duty](#) = No
- ? Material = Cold Rolled Steel
- ? Finish = None

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 - 1.40² [22 - 16]
- ? Wire Range (CMA) = 509 - 3,260

Industry Standards:

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Strip
- ? Packaging Quantity = 4,000

Other:

- ? Brand = AMP