


200686 -4 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

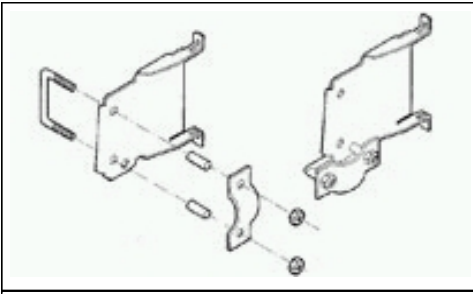

200686 -4

✓ [Active](#)

M Series Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Hardware
- ? Hardware Type = Strain Relief Clamp
- ? Strain Relief Type = Short
- ? Cable Opening Diameter = 13.46 x 8.51 mm
- ? None Mounting Hardware

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [CLAMP KIT, UNASSEMBLED, STRAIN RELIEF, 14 PLACE, RE...](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? [M SERIES PIN AND SOCKET CONNECTORS](#) (PDF, English)

Product Specifications:

- ? None Available

Application Specifications:

- ? [Ferrules For M Series Connectors](#) (PDF, English)

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Hardware
- ? Sleeve Material = Plastic
- ? Comment = Hardware supplied unassembled; Used with 14 position standard connectors.

Mechanical Attachment:

- ? [Hardware Type](#) = Strain Relief Clamp
- ? [Mounting Hardware](#) = None

Body Related Features:

- ? [Strain Relief Type](#) = Short
- ? [Cable Opening Diameter \(mm \[in\]\)](#) = 13.46 x 8.51 [.530 x .335]
- ? Strain Relief Clamp Material = Steel
- ? Strain Relief Clamp Plating = Nickel
- ? "U" Bolt Material = Stainless Steel
- ? Hex Nut Material = Steel
- ? Sleeve Color = Black
- ? Hex Nut Finish = Zinc with Non -Hexavalent Chromium

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- ? Brand = AMP