


204186-5 Product Details

[Live Product Chat](#)

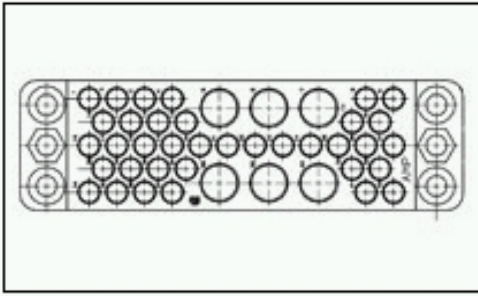

204186-5

TE Part Number: 204186-5

[Active](#)

[Add to Part List](#)

M Series Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Housing
- Number of Positions = 42
- Diallyl Phthalate Housing Material
- Plug
- Connector Type = Mixed

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [PLUG BLOCK, MALE, 42 POSN, MINI, M SERIES](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Ferrules For M Series Connectors](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Recommended Panel Cutout](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Housing
- [Number of Positions](#) = 42
- [Gender](#) = Plug
- Connector Type = Mixed
- Mount = Panel Mount
- Comment = Type II Pin Cavity-36 Places; Type IV Pin Cavity-6 Places

Mechanical Attachment:

- [Mounting Hardware](#) = None

Electrical Characteristics:

- [High Voltage](#) = No

Body Related Features:

- [Preloaded Contacts](#) = No
- [Center Fastener](#) = No

Housing Related Features:

- [Housing Material](#) = Diallyl Phthalate
- Housing Color = Green

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)