


205607-2 Product Details

[Live Product Chat](#)

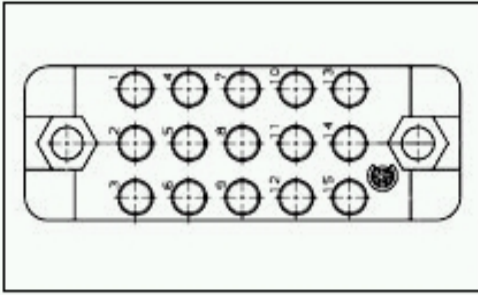

205607-2

TE Part Number: 205607-2

[Active](#)

[Add to Part List](#)

M Series Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Housing
- Number of Positions = 15
- Phenolic Housing Material
- Plug
- Connector Type = Posted

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

Documentation & Additional Information

Product Drawings:

- [BLOCK, PIN, 15 POSITION, M SERIES](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version E)
- [3D Model](#) (IGES, Version E)
- [3D Model](#) (STEP, Version E)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Housing
- [Number of Positions](#) = 15
- [Gender](#) = Plug
- Connector Type = Posted
- Mount = Panel Mount
- Comment = Accommodates 15 Type II or III+ Size #16 Socket Contacts.; Mates with AMP Part Number 205606-3.

Mechanical Attachment:

- [Mounting Hardware](#) = None

Body Related Features:

- [Center Fastener](#) = No

Housing Related Features:

- [Housing Material](#) = Phenolic
- Housing Color = Black

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)