




CONNECTORS

AUTOMOTIVE, TRUCK, BUS, & OFF-ROAD HOUSINGS

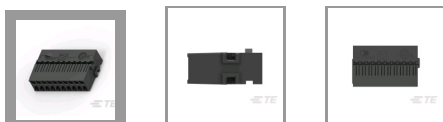

✓ Active

TE CONNECTIVITY (TE)

Carrier, 20P, GY LAC, Black

Generation Y Connector System

2098634-1

TE Internal Number: 2098634-1

EU RoHS Compliant

EU ELV Compliant

Connector Style Housing for female terminals

Mating Tab Width .64 mm [.025 in]

Connector System Wire-to-Board, Wire-to-Device

Number of Positions 20

Centerline (Pitch) 2.54 mm [.1 in]

[↓ PRODUCT DRAWING](#)
English

[↓ 3D PDF](#)

DOCUMENTATION

Product Drawings

CARRIER, 20 POSITION, 0.64mm GENERATION Y LAC CONNECTOR

PDF

English

CAD Files

3D PDF

PDF

3D

Customer View Model

2D_DXF.ZIP

English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Style Housing for female terminals

Connector System Wire-to-Board, Wire-to-Device

Sealable No

Hybrid Connector No

Primary Locking Feature Integrated in Housing

Strain Relief Add By Accessory

Row-to-Row Spacing 6 mm [.236 in]

Configuration Features

Number of Positions 20

Number of Rows 2

Body Features

Color Black

Cable Exit Angle 180°

Body Material PA GF

Contact Features

Mating Tab Width .64 mm [.025 in]

Mechanical Attachment

Mounting Feature No

Terminal Position Assurance Yes

Polarized Yes

Housing Features

Centerline (Pitch) 2.54 mm [.1 in]

Dimensions

Width 7.8 mm [.307 in]
Height 16.5 mm [.65 in]
Length 27.18 mm [1.07 in]

Usage Conditions

Operating Temperature Range (°C) -40 – 100

Operation/Application

Circuit Application Signal

Packaging Features

Packaging Method Package

Packaging Quantity 50

Other

Connector Position Assurance Capable No

Serviceable Yes

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
