


226177 -2 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

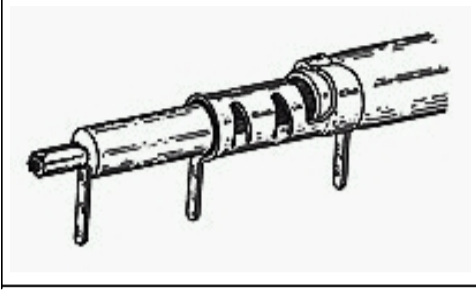

226177 -2

✓ [Active](#)

BRAID -PIC, RF Connectors

[Not EU RoHS or ELV Compliant](#) ([Find RoHS Compliant Alternates](#))

Product Highlights:

- ? Terminal
- ? Coaxial Cable Type (RG/U or Mfg.) = 174, 179, 179A, 179B, 187, 187A, 188, 188A, 316
- ? Crimp Type = Braid & Center Conductor Termination
- ? Connection Type = Permanent
- ? Strip

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [TERMINAL, PCB, COAXIAL, BRAID -PIC](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? [No title](#) (PDF, English)

Application Specifications:

- ? None Available

Instruction Sheets:

- ? [AMP* BRAID -PIC TERMINALS FOR PRINTED CIRCUIT BOARD A...](#) (PDF, English)

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Terminal
- ? [Crimp Type](#) = Braid & Center Conductor Termination
- ? [Connection Type](#) = Permanent
- ? Body Material = Brass

Termination Related Features:

- ? Coaxial Cable Termination Type = Crimp

Body Related Features:

- ? Body Plating = Tin

Configuration Related Features:

- ? [Coaxial Cable Type \(RG/U or Mfg.\)](#) = 174, 179, 179A, 179B, 187, 187A, 188, 188A, 316

Industry Standards:

- ? [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- ? [Lead Free Solder Processes](#) = Not reviewed for lead free solder process

Packaging Related Features:

- ? [Packaging Method](#) = Strip

Other:

- ? Brand = AMP