


282377 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

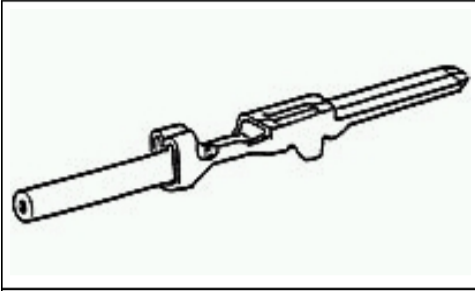

282377 -1

[Active](#)

MULTILOCK Connectors and Contacts

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? [Contact](#)
- ? [Terminate To Wire](#)
- ? [Tab Width = 1.78 mm](#)
- ? [Tab](#)
- ? [Wire Range = 0.30 -0.60² \[22-20\] mm \[AWG\]](#)

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [070 SRS MULTILOCK* TAB CONTACT](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? [.070 MLC Frame for New Panel Instruments](#) (PDF, English)
- ? [15 pos. hybrid connector with multilock .070 and .18...](#) (PDF, English)
- ? [12 Position Door to Body](#) (PDF, English)
- ? [070 SERIES MULTILOCK CONNECTOR FOR W.T.W. APPLICATION](#) (PDF, English)

Application Specifications:

- ? [APPLICATION SPECIFICATION FOR 070 SR. MULTILOCK* TAB](#) (PDF, English)

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Contact
- ? [Tab Width \(mm \[in\]\)](#) = 1.78 [0.07]
- ? [Tab/Receptacle](#) = Tab
- ? [Insulation Diameter \(mm \[in\]\)](#) = 1.40 - 1.90 [0.055 - 0.075]
- ? Proprietary Name = MULTILOCK
- ? Product Series = 070

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 -0.60² [22-20]

Contact Related Features:

- ? [Contact Material](#) = Brass
- ? [Contact Mating Area Plating Material](#) = Pre - Tin

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- ? [Terminate To](#) = Wire

Packaging Related Features:

- ? [Packaging Method](#) = Strip

Other:

- ? Brand = AMP