


32065 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

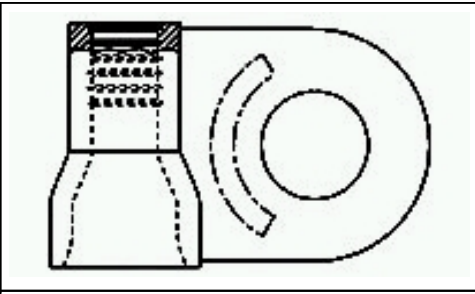

32065

Active

Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Terminal Shape = Ring Tongue
- ? Receptacle Style = Flag
- ? Body Style = DIAMOND GRIP
- ? Barrel Type = Closed Barrel
- ? Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [TERMINAL, RING TONGUE, FLAG, INSULATION SUPPORT, BUDGET](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Terminal Shape](#) = Ring Tongue
- ? [Receptacle Style](#) = Flag
- ? [Body Style](#) = DIAMOND GRIP
- ? [Barrel Type](#) = Closed Barrel
- ? [Wire/Cable Type](#) = Regular Wire
- ? [Insulation](#) = No
- ? [Insulation Support](#) = Insulation Support
- ? [Insulation Diameter \(mm \[in\]\)](#) = 3.18 [.125] Max.
- ? Stud Size = 6 [M3.5]
- ? [Stud Diameter \(mm \[in\]\)](#) = 3.51 [0.138]
- ? [Shape](#) = RING -090
- ? [Heavy Duty](#) = No
- ? [Material](#) = Copper
- ? [Finish](#) = Tin
- ? Tongue Material Thickness (mm [in]) = 0.84 [0.033]

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.30 - 1.40 ² [22 - 16]
- ? Wire Range (CMA) = 509 - 3,260

Industry Standards:

- ? Government/Industry Qualification = No
- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Loose Piece

Other:

- ? Brand = AMP