


 Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

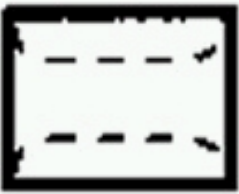

 Active

Always EU RoHS/ELV Compliant (Statement of Compliance)

? Splice
? Not Sealed
? Splice Type = Parallel
? Butt Splice Type = Standard
? Body Style = SOLISTRAND

[View all Features](#) | [Find Similar Products](#)

[Check Pricing & Availability](#)
[Search for Tooling](#)
[Product Feature Selector](#)
[Contact Us About This Product](#)

[SPLICE, PARALLEL, OVALED, SOLISTRAND ZTM](#) (PDF, English)

? None Available

? None Available

? None Available

? None Available

? None Available

Product Line Information

? Tooling

List all Documents

- ? Product Type = Splice
- ? Sealed = No
- ? Splice Type = Parallel
- ? Body Style = SOLISTRAND
- ? Insulation = No
- ? Material = Copper
- ? Finish = Tin
- ? Color = None

? Butt Splice Type = Standard
 ? Wire Range (mm [AWG]) = 8.00² [8]
 ? Wire Range (CMA) = 13,100 – 20,800
 ? Parallel Splice Type = Ovaled

- ? Government/Industry Qualification = No
- ? RoHS/ELV Compliance = RoHS compliant, ELV compliant
- ? Lead Free Solder Processes = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

? Packaging Method = Loose Piece

? Brand = AMP