


329056 Product Details

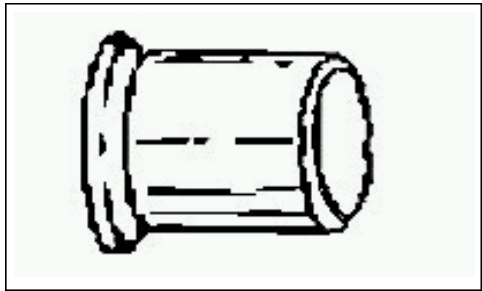

329056

 [Active](#)

Multiple Coaxial Contacts (COAXICON)

[Not EU RoHS or ELV Compliant](#) ([Find RoHS Compliant Alternates](#))

Product Highlights:

- ? Ferrule
- ? Ferrule Diameter = 6.58 mm
- ? Wire Diameter = 4.47 mm

[View all Features](#) | [Find Similar Products](#)

 **Live Product Chat** US Only
8:30am - 5pm ET, Mon - Fri

Quick Links

[Check Pricing & Availability](#)
[Search for Tooling](#)
[Product Feature Selector](#)
[Contact Us About This Product](#)

Documentation & Additional Information	
Product Drawings: ? FERRULE (PDF, English) Catalog Pages/Data Sheets: ? None Available Product Specifications: ? None Available Application Specifications: ? None Available Instruction Sheets: ? None Available CAD Files: ? None Available List all Documents	Additional Information: ? Product Line Information Related Products: ? Tooling

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: ? Product Type = Ferrule Body Related Features: ? Wire Diameter (mm [in]) = 4.47 [0.176] ? Ferrule Diameter (mm [in]) = 6.58 [0.259] ? Ferrule Material = Copper ? Ferrule Plating = Tin	Industry Standards: ? RoHS/ELV Compliance = Not ELV/RoHS compliant ? Lead Free Solder Processes = Not reviewed for lead free solder process Other: ? Brand = AMP