


## 332416 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

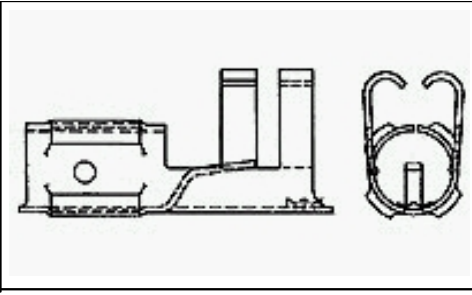

**332416**

✓ [Active](#)

### Miscellaneous Terminals

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

#### Product Highlights:

- ? Ignition Plug Contact
- ? Insulation Support
- ? Wire Range = 8.00 <sup>2</sup> [8] mm [AWG]
- ? Not For Use With Double Wire
- ? Carbon Steel Material

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- ? [ignition system terminal](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- ? None Available

#### Product Specifications:

- ? None Available

#### Application Specifications:

- ? None Available

#### Instruction Sheets:

- ? [AMP\\* IGNITION TERMINAL P/N 332416 AND CABLE SUPP... \(1\)](#) (PDF, English)
- ? [AMP\\* IGNITION TERMINAL P/N 332416 AND CABLE SUPP... \(2\)](#) (PDF, English)

#### CAD Files:

- ? None Available

#### Related Products:

- ? [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? Product Type = Ignition Plug Contact
- ? [Insulation Support](#) = Insulation Support
- ? Material = Carbon Steel
- ? Finish = Tin
- ? Insulation Diameter (mm [in]) = 7.00 [.276]
- ? Comment = For ignition cable 7.00 mm diameter.

#### Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 8.00 <sup>2</sup> [8]
- ? Double Wire = No
- ? Stock Thickness (mm [in]) = 0.51 [0.020]

#### Contact Related Features:

- ? Bulb = Without

#### Configuration Related Features:

- ? Diode = Without

#### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

#### Packaging Related Features:

- ? Packaging Method = Box

#### Other:

- ? Brand = Tyco Electronics