


350011 -3 Product Details


Live Product Chat US Only
 8:30am - 5pm ET, Mon - Fri

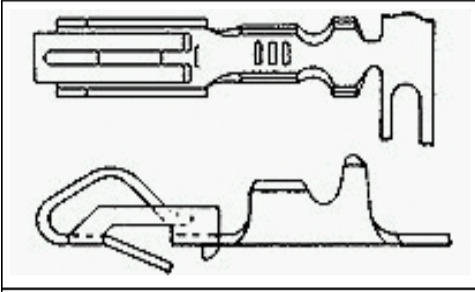

350011 -3

 [Active](#)

.100, .125, .156 Centerline Connectors (Crimp Snap Twin Leaf)

Always EU RoHS/ELV Compliant ([Statement of Compliance](#))

Product Highlights:

- ? Contact
- ? Contact Type = Bifurcated
- ? 2.54 mm Centerline
- ? Wire Termination Type = Crimp
- ? Wire Range = 0.20 -0.80² [24-18] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [CONTACT, LOOSE PIECE](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? [Connector, Edge, Bifurcated Leaf](#) (PDF, English)

Application Specifications:

- ? [Bifurcated Leaf Contact](#) (PDF, English)

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Contact
- ? [Wire Termination Type](#) = Crimp
- ? [Wire Insulation Diameter \(mm \[in\]\)](#) = 2.54 [0.100]

Mechanical Attachment:

- ? Contact Retention in Housing = Crimp Snap -In

Termination Related Features:

- ? [Solder Tail Contact Plating](#) = Pre -Tin

Body Related Features:

- ? [Centerline \(mm \[in\]\)](#) = 2.54 [0.100]
- ? [Wire Range \(mm \[AWG\]\)](#) = 0.20 -0.80² [24-18]

Contact Related Features:

- ? [Contact Type](#) = Bifurcated
- ? [Contact Mating Area Plating Material](#) = Pre -Tin
- ? Contact Material = Brass

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Contact Packaging Method](#) = Loose Piece

Other:

- ? Brand = AMP