

# 4MM^2,1 IN 1 OUT SPRING TERMINAL BLOCK

✓ ACTIVE

[Buchanan](#) | [Din Rail Terminal Block Systems](#)

TE Part # **2271559-4**

TE Internal #: **2271559-4**

Terminal Block Type : **Spring Terminal Block**

Block Type : **Standard**

Connector System : **Cable-to-Cable**

Number of Positions : **1**

Centerline (Pitch) : **6.15 mm [ .242 in ]**

[Add to List](#) ▾

[Similar Products](#)



**ORDER SAMPLES**

**Compatible Parts & Tooling**

## SHOP OUR DISTRIBUTORS

North America ▾

Request pricing, availability and customization options

**CONTACT US**



## We are here to help!

Get in touch with our product experts.



**CHAT WITH US**



**EMAIL US**



**CALL US**

### DOCUMENTS

### FEATURES

### PRODUCT COMPLIANCE

#### Product Drawings

4MM^2,1 IN 1 OUT SPRING TERMINAL BLOCK

[4MM^2,1 IN 1 OUT SPRING TERMINAL BLOCK](#)

English

#### CAD Files

3D PDF

[3D\\_CVM\\_CVM\\_2271559-4\\_A.pdf](#) 3D

Customer View Model

[ENG\\_CVM\\_CVM\\_2271559-4\\_A.2d\\_dxf.zip](#)

English

[ENG\\_CVM\\_CVM\\_2271559-4\\_A.3d\\_igs.zip](#)

English

[ENG\\_CVM\\_CVM\\_2271559-4\\_A.3d\\_stp.zip](#)

English

#### Product Specifications

Application Specification

[ENG\\_SS\\_114-137138\\_A3.pdf](#) English

Product Specification

[ENG\\_SS\\_108-137138\\_A3.pdf](#) English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type  
Features

Terminal Block Type : **Spring Terminal Block**  
Block Type : **Standard**  
Connector System : **Cable-to-Cable**  
Sealable : **No**  
Product Type : **Terminal Block**

Configuration  
Features

Number of Positions : **1**  
Number of Circuits : **1**  
Ground Function : **Without**  
Fuse Function : **Without**  
Switch Function : **Without**  
Number of Contacts : **1**

Electrical  
Characteristics

Current Rating (A): **30**  
Voltage Rating (VAC): **600**  
Continuous Current Rating (A):  
**30**

Contact Features

Contact Base Material : **Copper**  
Contact Configuration : **Quick Connect**  
Contact Current Rating (Max) (A):  
**30**  
Contact Plating Material : **Matte Tin**

Mechanical  
Attachment

Connector Mounting Type :  
**DIN Rail**

Housing Features

Centerline (Pitch) : **6.15 mm [ .242 in ]**  
Housing Color : **Red**  
Housing Material : **Nylon**

Dimensions

Wire Size : **28 – 10 AWG [ .08 – 4  
kcmil ]**

Usage Conditions

Operating Temperature Range (°C):  
**-40 – 105**

Operation/Application Circuit Application : **Power**

Industry  
Standards

UL Flammability Rating : **UL 94V-0**



Statement of  
Compliance

[Statement of Compliance pdf](#)

## Compatible Parts

[> Contact Product Support](#)

## Also in the Series | [Din Rail Terminal Block Systems](#)



Terminal Block  
Hardware (26)




Terminal Block  
Marking (4)




Terminal Blocks (158)


## Customers Also Bought

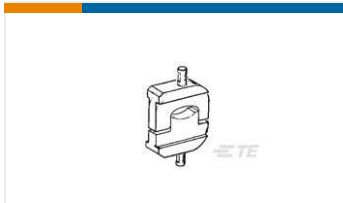


**TE Part #** 68085  
**DIE COPALUM IP**  
**69099 6**

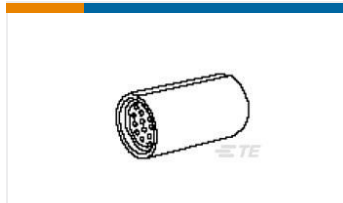

**TE Part #** 52746  
**SPLICE, COPALUM**  
**PARA 6**

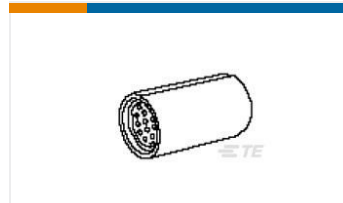

**TE Part #** 52791  
**SPLICE, COPALUM**  
**PARA 16-14**

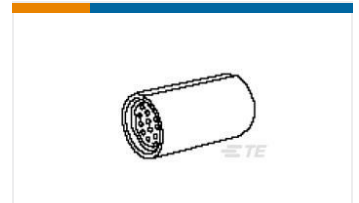

**TE Part #** 52792  
**SPLICE, COPALUM**  
**PARA 12-10**