


### 3-88637 -0 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

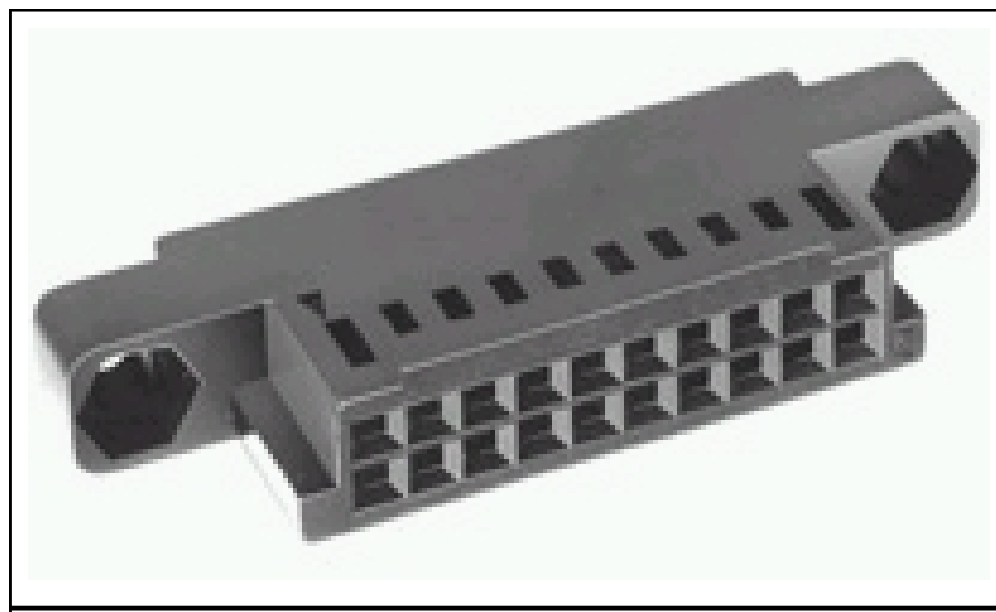

**3-88637 -0**

Active

#### Flexible Film Connectors

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

##### Product Highlights:

- ? Housing
- ? 2.54 mm Centerline
- ? Connector Type = Standard
- ? Number of Positions = 58
- ? Number of Rows = Dual

[View all Features](#) | [Find Similar Products](#)

#### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [View Contacts \(59\)](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

#### Documentation & Additional Information

##### Product Drawings:

- ? [HOUSING,RCPT,DBL ROW / W DETENTS,.100@22,FFC](#) (PDF, English)

##### Catalog Pages/Data Sheets:

- ? None Available

##### Product Specifications:

- ? None Available

##### Application Specifications:

- ? None Available

##### Instruction Sheets:

- ? None Available

##### CAD Files: ( [CAD Format & Compression Information](#) )

- ? [2D Drawing](#) (DXF, Version AE)
- ? [3D Model](#) (IGES, Version AE)
- ? [3D Model](#) (STEP, Version AE)

[List all Documents](#)

##### Additional Information:

- ? [Product Line Information](#)

##### Related Products:

- ? [Tooling](#)
- ? [Contacts \(59\)](#)

#### Product Features (Please use the Product Drawing for all design activity)

##### Product Type Features:

- ? [Product Type](#) = Housing
- ? [Connector Type](#) = Standard
- ? [Number of Positions](#) = 58
- ? [Mating Type](#) = Receptacle
- ? [Mating Connector Lock](#) = With
- ? [Mating Connector Lock Type](#) = Detent
- ? [Mating Polarization](#) = With
- ? [Mounting Ears](#) = With
- ? Flame Retardant = Yes
- ? Color = Black
- ? Comment = Use Extraction Tool No. 91093 for round wire contacts.; Ink Stamped -1

##### Mechanical Attachment:

- ? [Panel Attachment](#) = With

##### Body Related Features:

- ? [Centerline \(mm \[in\]\)](#) = 2.54 [0.100]
- ? [Number of Rows](#) = Dual

##### Housing Related Features:

- ? Housing Material = Thermoplastic
- ? Housing Flammability Rating = UL 94V -0

##### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

##### Conditions for Usage:

- ? [Terminate To](#) = FFC Cable

##### Other:

- ? Brand = AMP