




+ RELAYS, CONTACTORS & SWITCHES

DIP & SIP SWITCHES

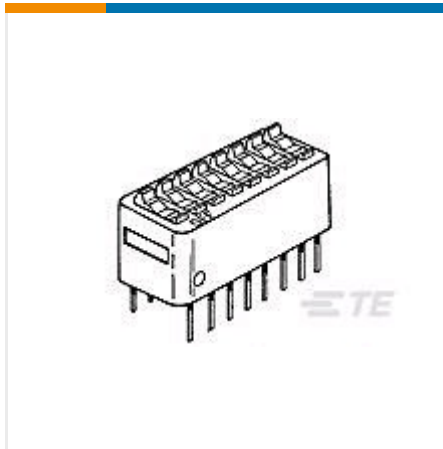

✓ Active

TE CONNECTIVITY (TE)

## DIP SW 10 POSN SEALED

Alcoswitch | Alcoswitch DIP , Alcoswitch DIP 7000 & 7100

4-5435640-1

TE Internal Number: 4-5435640-1

EU RoHS Compliant

EU ELV Compliant

**Product Type** Switch

**Contact Mating Area Plating Material** Gold

**Housing Color** Blue

**Housing Material** Polyester GF

**Auto-Insertable** No

↓ **PRODUCT DRAWING**  
English

↓ **3D PDF**

### DOCUMENTATION

Product Drawings

#### **SWITCH ASSY, DIP, TYPE C, 7100 SERIES, SPST, STANDARD**

PDF

**English**

CAD Files

#### **Customer View Model**

3D\_IGS.ZIP

**English**

#### **Customer View Model**

3D\_STP.ZIP

**English**

## Customer View Model

2D\_DXF.ZIP

English

## 3D PDF

PDF

English

---

Product Specifications

Application Specification

## Dual In-Line Package (DIP) Programming Switches (7000 And 7100 Series)

PDF

English

---

Product Environmental Compliance

TE Material Declaration

## MD\_4-5435640-1\_100220162355\_dmtec

PDF

English

---

Instruction Sheets

Instruction Sheet (U.S.)

## Dual In-Line Package (DIP) Programming Switches (7000 And 7100 Series)

PDF

English

---

## FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

---

Product Type Features

**Product Type** Switch

**Sealed** Yes

**Switch Type** DIP

**Actuator Style** Rocker (Top Actuated)

---

Configuration Features

**Number of Switches** 10

**Configuration (Pole-Throw)** Single Pole - Single Throw

**Number of Positions** 10

---

Electrical Characteristics

**Voltage Rating (VDC)** 40

---

Body Features

**Seal Type** Standard

---

#### Contact Features

**Contact Mating Area Plating Material** Gold  
**Auto-Insertable** No  
**Contact Current Rating (A)** 1  
**Contact Base Material** Copper Alloy  
**Contact Mating Area Plating Thickness (µin)** 30  
**Solder Tail Contact Plating** Tin

---

#### Termination Features

**Termination Post Length** 3.56 mm [ .14 in ]

---

#### Mechanical Attachment

**Mounting Type** Through Hole  
**Mounting Angle** Vertical

---

#### Housing Features

**Housing Color** Blue  
**Housing Material** Polyester GF  
**Centerline** 2.54 mm [ .1 in ]

---

#### Dimensions

**Length** 27.43 mm [ 1.08 in ]  
**Height** 8.636 mm [ .34 in ]

---

#### Packaging Features

**Packaging Quantity** 11  
**Packaging Method** Box & Tube, Tube

---

### PRODUCT COMPLIANCE



Statement of Compliance

**Statement of Compliance**

PDF

---