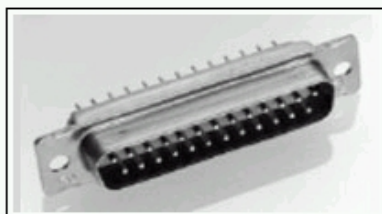


1757826-3 Product Details

[Share](#) [Print](#) [Email](#)


1757826-3
(M24308/2-299)

TE Internal Number: 1757826-3

Active

[View 3D PDF](#)

Subminiature D Pins/Sockets for MIL-C-24308 and MIL-C-39029

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Connector
- Product Series = 90
- Connector Style = Receptacle
- Accepts Contact Gender = Socket
- Density = High

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [AMPLIMITE RECEPTACLE ASSY,SIZE 1 THRU 6 SERIES 90 WI...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version G)
- [3D Model](#) (IGES, Version G)
- [3D Model](#) (STEP, Version G)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Insert Arrangement](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Connector
- [Product Series](#) = 90
- [Shell Size](#) = 3
- [Shell Material](#) = Steel
- [Termination Method to Wire/Cable](#) = Crimp
- [Mounting Hole Diameter \(mm \[in\]\)](#) = 3.05 [.120]

Body Features:

- [Number of Positions](#) = 44
- [Blindmate](#) = No
- [Non-Magnetic](#) = No
- [Rear Grommet](#) = No
- [Power/Signal/Coax Combination](#) = No
- [Shell Plating](#) = Zinc
- [Mount Style](#) = Dual Floating Bushing
- [Retention Clip Material](#) = Stainless Steel

Contact Features:

- [Accepts Contact Gender](#) = Socket
- [Contact Size](#) = 22
- [Contact Style](#) = Crimp Snap-in

Housing Features:

- [Connector Style](#) = Receptacle

Configuration Features:

- [Density](#) = High

Industry Standards:

- [Government/Industry Qualification](#) = Yes
- [Government/Industry Part Number](#) = M24308/2-299
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant
- [NASA Qualification](#) = No

Conditions for Usage:

- [Applies To](#) = Wire/Cable

Other:

- [Brand](#) = AMP
- [Comment](#) = "F" is stamped on connectors following M24308 part number as required. "F" designates cadmium shell plating.; Supplied without sockets.

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

