


41968-2 Product Details

[Live Product Chat](#)

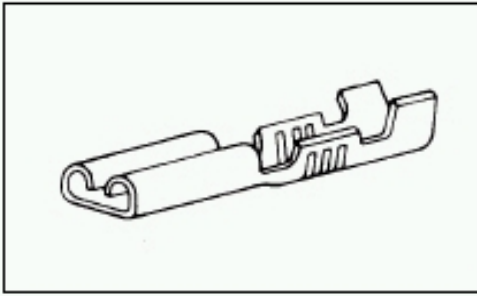

41968-2

TE Part Number: 41968-2

Active

[Add to Part List](#)

[View 3D PDF](#)

FASTON Uninsulated Receptacles & Housings

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Receptacle
- Tab Fit = 6.35 x 0.81 mm
- Board Mount = No
- Receptacle Style = Straight
- Insulation Support

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [RECEPTACLE, FASTON, .250 SERIES \(PDF, English\)](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Wire Preparation And Crimp Inspection Guide \(PDF, English\)](#)

Instruction Sheets:

- [Crimping Head for FASTON Terminals \(PDF, English\)](#)

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing \(DXF, Version G\)](#)
- [3D Model \(IGES, Version G\)](#)
- [3D Model \(STEP, Version G\)](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Receptacle
- [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- [Receptacle Style](#) = Straight
- [Insulation Support](#) = Insulation Support
- [Wire/Cable Type](#) = Stranded
- [Insulation Diameter \(mm \[in\]\)](#) = 2.29-3.30 [.090-.130]
- [Insertion Force](#) = Normal
- [Material](#) = Brass
- [Finish](#) = None
- [Crimp Type](#) = F-Crimp
- CSA Certified = Yes

Mechanical Attachment:

- [Board Mount](#) = No

Body Related Features:

- [Weld Tab](#) = Without
- [Wire Range \(mm \[AWG\]\)](#) = 0.30-0.90² [22-18]
- UL Rating = Listed
- Stock Thickness (mm [in]) = 0.41 [0.016]

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Loose Piece

Other:

- [For Hermetic Header Tab](#) = No
- [Line](#) = Premier
- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)