


521165-1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

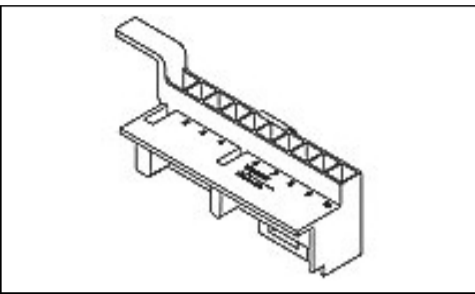

521165-1

[Active](#)

Timer Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Motor Housing
- Connector Type = Standard Timer
- Tab Fit = 3.18 x 0.51 mm
- Number of Positions = 10
- Housing Color = Black

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [MOTOR HOUSING,10 CIRCUIT](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Standard Timer Connectors](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version E)
- [3D Model](#) (IGES, Version E)
- [3D Model](#) (STEP, Version E)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Motor Housing
- [Connector Type](#) = Standard Timer
- Tab Fit (mm [in]) = 3.18 x 0.51 [.125 x .020]
- Number of Positions = 10

Housing Related Features:

- Housing Color = Black
- Housing Material = Nylon 66

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP