




5435668-5 Product Details

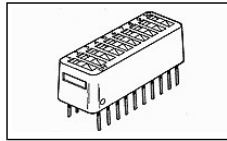

5435668-5

Active

DIP, Rotary DIP, SIP Switches and DIP Shunts - Standard

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- DIP Switch
- PCB Mount Style = Thru Hole
- Single Pole - Single Throw Configuration (Pole-Throw)
- Actuator Style = Rocker (Top Actuated)
- Not Sealed

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information	
Product Drawings: <ul style="list-style-type: none"> ● SWITCH ASSY, DIP, TYPE C, 7100 SERIES, SPST, LOW PROFILE (PDF, English) 	Additional Information: <ul style="list-style-type: none"> ● Product Line Information
Catalog Pages/Data Sheets: <ul style="list-style-type: none"> ● None Available 	Additional Product Images: <ul style="list-style-type: none"> ● Contact Arrangement ● Recommended PC Board Hole Pattern
Product Specifications: <ul style="list-style-type: none"> ● None Available 	Related Products: <ul style="list-style-type: none"> ● Tooling
Application Specifications: <ul style="list-style-type: none"> ● Dual In-Line Package (DIP) Programming Switches (700... (PDF, English) 	
Instruction Sheets: <ul style="list-style-type: none"> ● Dual In-Line Package (DIP) Programming Switches (700... (PDF, English) 	
CAD Files: <ul style="list-style-type: none"> ● None Available 	
List all Documents	

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: <ul style="list-style-type: none"> ● Product Type = DIP Switch ● PCB Mount Style = Thru Hole ● Configuration (Pole-Throw) = Single Pole - Single Throw ● Actuator Style = Rocker (Top Actuated) ● Sealed = No ● Number of Switches = 6 ● Comment = All switches are bottom sealed. 	Housing Related Features: <ul style="list-style-type: none"> ● Low Profile = Yes ● Housing Color = Blue ● Housing Material = Polyester GF ● Housing Flammability Rating = UL 94V-0
Termination Related Features: <ul style="list-style-type: none"> ● Termination (Solder) Post Length (mm [in]) = 3.56 [0.140] 	Industry Standards: <ul style="list-style-type: none"> ● RoHS/ELV Compliance = RoHS compliant, ELV compliant ● Lead Free Solder Processes = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C ● RoHS/ELV Compliance History = Always was RoHS compliant
Body Related Features: <ul style="list-style-type: none"> ● Series = 7100 ● Centerline (mm [in]) = 2.54 [0.100] 	Packaging Related Features: <ul style="list-style-type: none"> ● Packaging Quantity = 18
Contact Related Features: <ul style="list-style-type: none"> ● Auto-Insertable = No ● Contact Material = Copper Alloy ● Contact Mating Area Plating = Gold (30) over Nickel (50) 	Other: <ul style="list-style-type: none"> ● Brand = Alcoswitch

[Provide Website Feedback](#) | [Contact Customer Support](#)