

Products

Documentation


Resources

My Account

Customer Support

[Home](#) > [Products](#) > [By Type](#) > [CHAMP Connectors](#) > [Product Feature Selector](#) > Product Details

5552960 - 5 Product Details

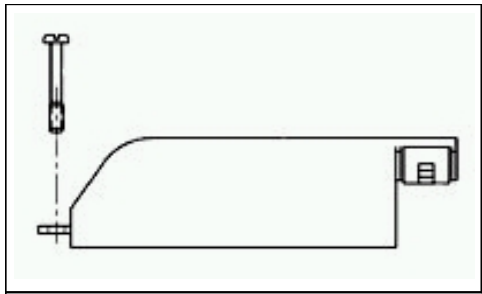

5552960 - 5

 [Active](#)

2.16 [.085] Accessories and Hardware

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Cover/Cable Clamp Kit
- ? Cover Type = Strain Relief
- ? Cover Style = Standard
- ? Slide - On Cover/Strain Relief Retention Method
- ? 90° Cable Exit Angle

[View all Features](#) | [Find Similar Products](#)

 **Live Product Chat** US Only
8:30am - 5pm ET, Mon - Fri

Quick Links

[Check Pricing & Availability](#)
[Search for Tooling](#)
[Product Feature Selector](#)
[Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings: ? COVER KIT, 90 DEGREES, 50 POSITION, SCREW LOCK, CHAMP (PDF, English) Catalog Pages/Data Sheets: ? None Available Product Specifications: ? None Available Application Specifications: ? None Available Instruction Sheets: ? None Available CAD Files: ? None Available	Additional Information: ? Product Line Information Related Products: ? Tooling
List all Documents	

Product Features (Please use the Product Drawing for all design activity)

Product Type Features: ? Product Type = Cover/Cable Clamp Kit ? Cover Type = Strain Relief ? Cover Style = Standard ? Number of Positions = 50 ? Cable Outer Diameter (mm [in]) = 12.70 – 13.97 [0.500 – 0.550] ? Color = Black Mechanical Attachment: ? Cover/Strain Relief Retention Method = Slide - On Body Related Features: ? Cable Exit Angle = 90°	Industry Standards: ? RoHS/ELV Compliance = RoHS compliant, ELV compliant ? Lead Free Solder Processes = Not relevant for lead free process ? RoHS/ELV Compliance History = Always was RoHS compliant Operation/Application: ? Application = Cable -to -Cable Packaging Related Features: ? Packaging Quantity = 100 Kits ? Packaging Method = Bulk Other: ? Brand = AMP
---	--