


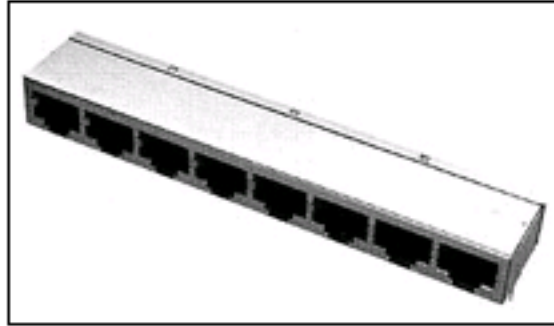

557566-1 Product Details

[Share](#) | [Print](#) | [Email](#)


557566-1

TE Internal Number: 557566-1

Superseded

[Search for Replacement Parts](#)

[View 3D PDF](#)

PCB Mounted Jacks - Single Port, Multi-port and Stacked

5 of 6 EU RoHS/ELV Compliant (Find RoHS Compliant Alternates/Statement of Compliance)

Product Highlights:

- Connector
- Preloaded
- Multiple Port Configuration
- 1 x 8 Jack Configuration
- Jack Type = RJ45

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- [Eight Position Multiple Port Right Angle Modular Jacks \(PDF, English\)](#)
- [High Performance Modular Plugs & Jacks, PCB Mounted \(PDF, English\)](#)

Application Specifications:

- [Modular Jacks \(PDF, English\)](#)

Instruction Sheets:

- None Available

CAD Files: (CAD Format & Compression Information)

- [2D Drawing \(DXF, Version B\)](#)
- [3D Model \(IGES, Version B\)](#)
- [3D Model \(STEP, Version B\)](#)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Connector
- Jack Type = RJ45
- PCB Mounting Orientation = Side Entry (Right Angle)
- PCB Mount Style = Through Hole
- Termination Method to PC Board = Solder
- Performance Category = Cat 4
- LED = Without
- Grounding Options = Without
- Panel Stops = Without
- Keyed = No
- Profile = Standard
- Color = Black

Mechanical Attachment:

- Panel Mount Retention = Without

Electrical Characteristics:

- Shielded = No

Termination Features:

- Solder Tail Contact Plating = Tin-Lead over Nickel

Dimensions:

- PCB Tail Length (mm [in]) = 3.56 [0.140]

Body Features:

- Inverted Jack Face = No
- Number of Contacts Loaded, RJ45 (8 Positions) = 8

Contact Features:

- Contact Plating, Mating Area, Material = Gold (50)
- Contact Base Material = Phosphor Bronze

Housing Features:

- Housing Material = High Temperature Nylon
- UL Flammability Rating = UL 94V-0

Configuration Features:

- Preloaded = Yes
- Port Configuration = Multiple
- Jack Configuration = 1 x 8
- Number of Positions = 8
- Number of Contacts Loaded = 8

Industry Standards:

- RoHS/ELV Compliance = ELV compliant, 5 of 6 Compliant
- Lead Free Solder Processes = Wave solder capable to 240°C

Packaging Features:

- Packaging Method = Tray
- Packaging Quantity = 10

Product Availability:

- Region = Asia, North America

Other:

- Brand = AMP
- Comment = On any modular jack, Terminal No. 1 is the terminal to the extreme left as you face the jack opening, tab notch down.

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

