


## 61115 -1 Product Details

**Live Product Chat** US Only  
8:30am - 5pm ET, Mon - Fri

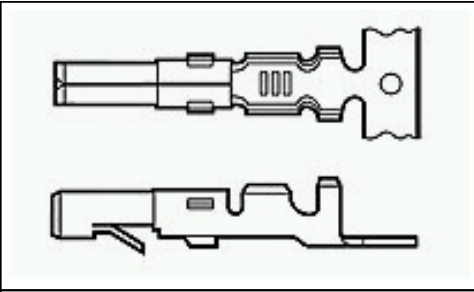

**61115 -1**

[Active](#)

**.200" Centerline, 250 V, 13 A max.**

[Always EU RoHS/ELV Compliant](#) ( [Statement of Compliance](#) )

**Product Highlights:**

- ? Contact
- ? Contact Diameter = 1.97 mm
- ? Strip
- ? Contact Type = Socket
- ? Wire Range = 0.20 -0.80<sup>2</sup> [24-18] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

**Quick Links**

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

**Product Drawings:**

- ? [socket, commercial mate -n-lok](#) (PDF, English)

**Catalog Pages/Data Sheets:**

- ? None Available

**Product Specifications:**

- ? None Available

**Application Specifications:**

- ? [MATE-N-LOK Commercial Pin And Socket Contacts](#) (PDF, English)
- ? [ER\\*\\*MATE -N-LOK Receptacle 61115](#) (PDF, English)
- ? [MATE-N-LOK Commercial Pin and Socket Contacts](#) (PDF, Japanese)

**Instruction Sheets:**

- ? None Available

**CAD Files:** ( [CAD Format & Compression Information](#) )

- ? [2D Drawing](#) (DXF, Version AA)
- ? [3D Model](#) (IGES, Version AA)
- ? [3D Model](#) (STEP, Version AA)

[List all Documents](#)

**Additional Information:**

- ? [Product Line Information](#)

**Related Products:**

- ? [Tooling](#)

### Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- ? Product Type = Contact
- ? Wire Insulation Diameter (mm [in]) = 2.54 [0.100]
- ? Connector Line = Commercial MATE -N-LOK

**Electrical Characteristics:**

- ? Voltage (VAC) = 250
- ? Current Rating (Amps.) = 13

**Termination Related Features:**

- ? Solder Tail Contact Plating = Pre -Tin

**Body Related Features:**

- ? Contact Diameter (mm [in]) = 1.97 [0.078]
- ? Wire Range (mm [AWG]) = 0.20 -0.80<sup>2</sup> [24-18]

**Contact Related Features:**

- ? Contact Type = Socket
- ? Contact Material = Brass

**Industry Standards:**

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

**Packaging Related Features:**

- ? Packaging Method = Strip
- ? Packaging Quantity = 7,500

**Other:**

- ? Brand = AMP