


63520 -1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

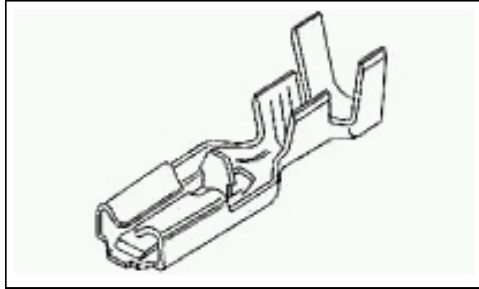

63520 -1

✓ [Active](#)

Positive Lock Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Receptacle
- ? Tab Fit = 4.75 x 0.81 mm
- ? Line = Mark II
- ? Receptacle Style = Straight
- ? Wire Range = 0.50 -1.40² [20-16] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [RECEPTACLE, POSITIVELOCK, .187 SERIES](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? [Series 187 MK II and MK III Series 250 MK II and MK ...](#) (PDF, English)

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Additional Product Images:

- ? [Recommended Mating Tab](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Receptacle
- ? [Tab Fit \(mm \[in\]\)](#) = 4.75 x 0.81 [.187 x .032]
- ? [Receptacle Style](#) = Straight
- ? [Insulation Diameter \(mm \[in\]\)](#) = 2.29 -3.30 [.090 -.130]
- ? [Material](#) = Brass
- ? [Finish](#) = Tin
- ? [Keyed](#) = No

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.50 -1.40² [20-16]
- ? [Position Keyed](#) = None
- ? Stock Thickness (mm [in]) = 0.30 [0.012]

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Strip

Other:

- ? [Line](#) = Mark II
- ? Brand = AMP