


641257-1 Product Details

[Live Product Chat](#)

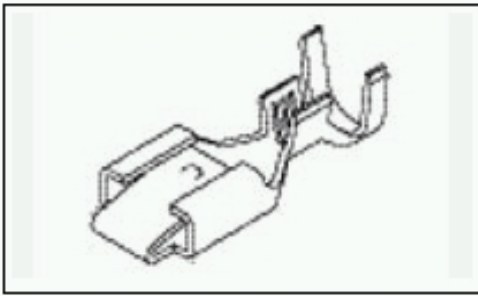

641257-1

TE Part Number: 641257-1

[Active](#)

[Add to Part List](#)

Miscellaneous Terminals

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- .250 Blade Receptacle
- Insulation Support
- Wire Range = 0.80-2.00² [18-14] mm [AWG]
- Not For Use With Double Wire
- Brass Material

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [RECEPTACLE, .250 BLADE, LOOSE PIECE](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Special 250 Blade Receptacle Terminal](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = .250 Blade Receptacle
- [Insulation Support](#) = Insulation Support
- Material = Brass
- Finish = None
- Insulation Diameter (mm [in]) = 3.90 [.154] Max.

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.80-2.00² [18-14]
- Double Wire = No

Contact Related Features:

- Bulb = Without

Configuration Related Features:

- Diode = Without

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- Packaging Method = Loose Piece
- Packaging Quantity = 100

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)