


737190-2 Product Details

 **Live Product Chat** US Only
8:30am - 5pm ET, Mon - Fri

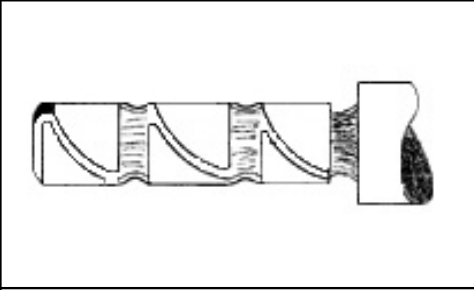

737190-2

 [Active](#)

Pins and Receptacles

[Converted to EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Wire Pin
- Without Insulation Support
- Wire/Cable Type = Regular Wire
- Wire Range = 0.75-1.00² [18.5-17] mm [AWG]
- Brass Material

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [punta rigida circular](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Wire Pin
- Insulation Support = No
- [Wire/Cable Type](#) = Regular Wire
- [Material](#) = Brass
- Finish = None

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.75-1.00² [18.5-17]
- Stock Thickness (mm [in]) = 0.25 [0.010]

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Converted to comply with RoHS directive

Packaging Related Features:

- Packaging Method = Strip

Other:

- Brand = AMP