


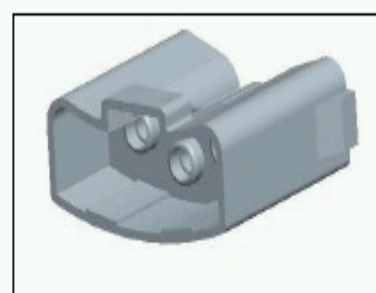

## 794099-1 Product Details

[Share](#) | [Print](#) | [Email](#)


794099-1

.250" Centerline, 600 V, 19 - 36 A max

Always EU RoHS/ELV Compliant (Statement of Compliance)

**Product Highlights:**

- Universal MATE-N-LOK Product Line
- Wire-to-Wire
- Applies To Wire/Cable
- Connector
- Housing

[View all Features](#)

**Quick Links**

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [View Mating Products \(1\)](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

TE Internal Number: 794099-1

Active

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

### Documentation & Additional Information

**Product Drawings:**

- [HOUSING, 3 POSITION, FAN MOTOR CONNECTOR MATE, UNIVE... \(PDF, English\)](#)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- None Available

**Application Specifications:**

- [Universal MATE-N-LOK Connectors \(PDF, English\)](#)

**Instruction Sheets:**

- None Available

**CAD Files:**

- None Available

**Additional Information:**

- [Product Line Information](#)

**Related Products:**

- [Tooling](#)
- [Mating Products \(1\)](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- Product Line = Universal MATE-N-LOK
- Product Type = Connector
- Connector Type = Housing
- Sealed = No
- CSA File Number = LR 7189

**Mechanical Attachment:**

- Contact Retention = Without
- Mating Retention Type = Positive Lock
- Panel Mount Retention = Without

**Electrical Characteristics:**

- Operating Voltage Reference = AC/DC
- Operating Voltage (VAC) = 600
- Operating Voltage (VDC) = 600

**Body Features:**

- Mating Retention = With
- Assembly Integration Feature = Without

**Contact Features:**

- Contact Type = Pin or Socket
- Contact Layout = Staggered
- Multiple Contact Types = Without

**Housing Features:**

- Centerline (mm [in]) = 7.24 [0.285]
- Housing Material = Nylon - GF
- Housing Color = Natural
- Mating Alignment = With
- Mating Alignment Type = Polarization

**Configuration Features:**

- Number of Positions = 3
- Strain Relief = Without

**Industry Standards:**

- Agency/Standard = CSA, UL
- UL Flammability Rating = UL 94V-2
- RoHS/ELV Compliance = RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant
- VDE Tested = Yes
- UL Rating = Recognized
- UL File Number = E28476
- CSA Rating = Certified

**Environmental:**

- Operating Temperature (°C [°F]) = -55 - +125 [-67 - +257]

**Conditions for Usage:**

- Applies To = Wire/Cable
- Glow Wire Rating = Standard Part - Not Glow Wire
- For Use With = 03P Fan Motor Connector Housing P/N 770855

**Operation/Application:**

- Application Use = Wire-to-Wire

**Packaging Features:**

- Packaging Method = Package
- Packaging Quantity = 1

**Other:**

- Brand = AMP

#### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

#### Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

#### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

#### Keep Me Informed

