


796056 -7 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

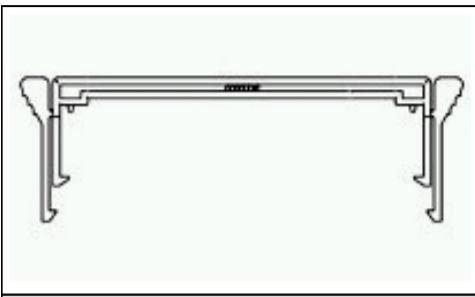

796056 -7

✔ [Active](#)

.050 Series Cable Connectors (SCSI)

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Hardware
- ? Plug
- ? Hardware Type = Strain Relief with Latches
- ? Number of Positions = 68
- ? Ribbon Cable Centerline Spacing = .64 mm

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [LATCH, .025 CENTERLINE, .050 SERIES AMPLIMITE@PZTM](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? [Connector, AMPLIMITE, Shielded, .050 Series](#) (PDF, English)

Application Specifications:

- ? [AMPLIMITE .050 Series Insulation Displacement and Pr...](#) (PDF, English)
- ? [AMPLIMITE .050 Series Feed -Through Connectors for 0...](#) (PDF, English)

Instruction Sheets:

- ? [Manual Arbor Frame Assembly 58024 -1](#) (PDF, English)
- ? [AMP* REPAIR TOOL 58430 -1 FOR AMPLIMITE* .050 -SERIES ...](#) (PDF, English)
- ? [AMPLIMITE .050 Series Connectors \(Round -to -Flat Cable\)](#) (PDF, English)
- ? [Installation and Use of Mass Termination Tooling](#) (PDF, English)
- ? [Cover Lacing Fixture 91293 -1 for AMPLIMITE .050 Seri...](#) (PDF, English)
- ? [AMP* MANUAL MINIATURE APPLICATOR FRAME ASSEMBLY 91295 -1](#) (PDF, English)
- ? [Cover Closing Kits and Staple Inserter Kit](#) (PDF, English)
- ? [Tooling Kit 768900 -1](#) (PDF, English)

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Hardware
- ? [Gender](#) = Plug
- ? Number of Positions = 68
- ? [Mating Connector Lock](#) = Without
- ? [Product Series](#) = Series III
- ? Material = Thermoplastic
- ? Color = Black
- ? Comment = Use with Plug Part Number 786090 -7

Mechanical Attachment:

- ? Hardware Type = Strain Relief with Latches

Body Related Features:

- ? Ribbon Cable Centerline Spacing (mm [in]) = 0.64 [0.025]

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- ? Brand = AMP