


796380-1 Product Details

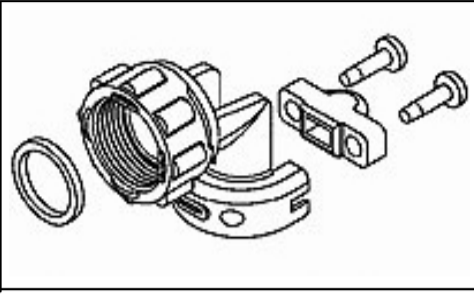

796380-1

✓ [Active](#)

CPC Accessories

[Not EU RoHS or ELV Compliant](#) ([Find RoHS Compliant Alternates](#))

Product Highlights:

- Cable Clamp
- Shell Size = 13
- Body Style = Right Angle
- Cable Diameter (Max.) = 11.51 mm
- Nylon Cable Clamp Material

[View all Features](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [CABLE CLAMP KIT, UNASSEMBLED, RIGHT ANGLE, SIZE 13, CPC](#) (PDF, English)

Catalog Pages/Data Sheets:

- [CIRCULAR CONNECTORS FOR COMMERCIAL SIGNAL AND POWER ...](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [3D Model](#) (STEP, Version C)
- [3D Model](#) (IGES, Version C)
- [2D Drawing](#) (DXF, Version C)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product Usage](#)
- [Product Usage](#)
- [Product Usage](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Cable Clamp
- [Shell Size](#) = 13
- [Body Style](#) = Right Angle
- [Screw Size](#) = 5-20 Self-Tapping

Body Related Features:

- [Cable Diameter \(Max.\) \(mm \[in\]\)](#) = 11.51 [0.453]
- [Cable Clamp Material](#) = Nylon
- [Cover](#) = Without
- [Cable Clamp Color](#) = Black
- [Cable Clamp Flammability Rating](#) = UL94V-0

Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

Packaging Related Features:

- [Packaging Method](#) = Individual

Other:

- [Brand](#) = AMP