


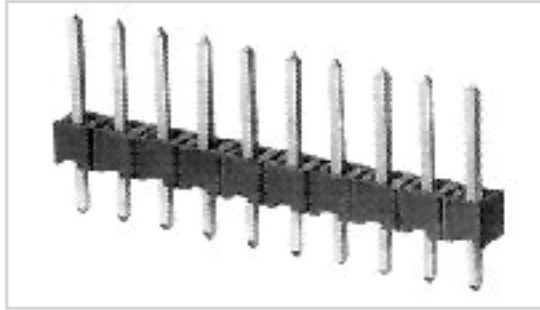

# 826629-8 Product Details

[Share](#) | [Print](#) | [Email](#)


## .100 inch AMPMODU Headers

AMPMODU II HEADER

826629-8

TE Internal Number: 826629-8

Active

[View 3D PDF](#)

**Product Highlights** [View All](#)

- Connector
- Header Type = Breakaway
- 8 Positions
- Mating Post Length = 6.70 mm
- Row-to-Row Spacing = 2.54 mm

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

**Please Note:**  
Use the Product Drawing for all design activity

Product Type Features	
Product Type	Connector
Mount Angle	Vertical
PCB Mount Retention	Without
Board Standoff	Without
Mating Connector Lock	Without
Profile	Standard
Mechanical Attachment	
Mounting Ears	Without
Panel Mount Retention	Without
Termination Features	
Termination Post Length (mm [in])	3.20 [0.1259]
Dimensions	
Mating Post Length (mm [in])	6.70 [0.264]
Body Features	
Header Type	Breakaway
Row-to-Row Spacing (mm [in])	2.54 [0.100]
Selectively Loaded	No
Mount Type	Printed Circuit Board
Contact Features	
Contact Plating, Mating Area, Material	Gold (30)
Solder Tail Contact Plating	Tin
Contact Base Material	Phosphor Bronze

Housing Features	
Housing Material	Thermoplastic
Configuration Features	
Number of Positions	8
Number of Rows	1
Surface Mount Compatible	No
Industry Standards	
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
RoHS/ELV Compliance History	Always was RoHS compliant
UL Flammability Rating	UL 94V-0
Conditions for Usage	
High Temperature Housing	No
Operation/Application	
High Speed Serial Data Connector	No
Packaging Features	
Packaging Quantity	500
Other	
Brand	AMP

### Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

#### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

#### Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

#### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

#### Keep Me Informed

