


828278-5 Product Details

[Live Product Chat](#)

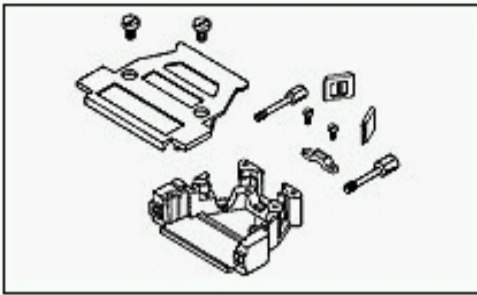

828278-5

TE Part Number: 828278-5

[Active](#)

[Add to Part List](#)

Cable Clamps

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Backshell/Cable Clamp
- Cable Clamp Type = Two-Piece RFI/EMI Shield
- Straight(180°)/45° Cable Exit Angle
- Cable Insulation Diameter = 10.00 mm
- Number of Positions = 25

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [COVER FOR HD-20 25POLIG](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version A2)
- [3D Model](#) (IGES, Version A2)
- [3D Model](#) (STEP, Version A2)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Backshell/Cable Clamp
- [Cable Clamp Type](#) = Two-Piece RFI/EMI Shield
- Number of Positions = 25
- [Shell Size](#) = 3
- [Shielded](#) = Yes
- [Screws and Retainer Clips](#) = Without
- [Grommets](#) = Without
- [Slide Latch](#) = Without
- Thread Size = 4-40

Body Related Features:

- [Cable Exit Angle](#) = Straight(180°)/45°
- [Cable Insulation Diameter \(mm \[in\]\)](#) = 10.00 [0.393]
- Cable Clamp Material = Polycarbonate
- Shield Plating = Bright Nickel over Copper
- Cover Flammability Rating = UL 94V-0

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Individual Kit
- Packaging Quantity = 50

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)