


85920-1 Product Details

[Live Product Chat](#)

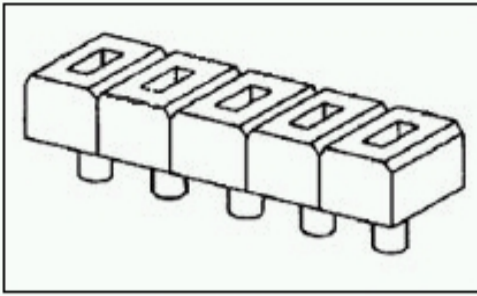

85920-1

TE Part Number: 85920-1

[Active](#)

[Add to Part List](#)

.100 inch AMPMODU Headers

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Bushing Insulator
- Number of Positions = 5
- 2.54 mm Centerline, Matrix
- Nylon Housing Material

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [BUSHING INSULATOR, AMPMODU MINIATURE, .100 SPACING](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- [INSTALLATION PROCEDURES FOR AMPMODU* MOD II POSTS](#) (PDF, English)

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Bushing Insulator
- [Number of Positions](#) = 5
- Color = Natural
- For Use With = AMPMODU Mod II Posts

Body Related Features:

- [Centerline, Matrix \(mm \[in\]\)](#) = 2.54 [.100]

Housing Related Features:

- Housing Material = Nylon

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP

[Provide Website Feedback](#) | [Need Help?](#)