


880646 -5 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

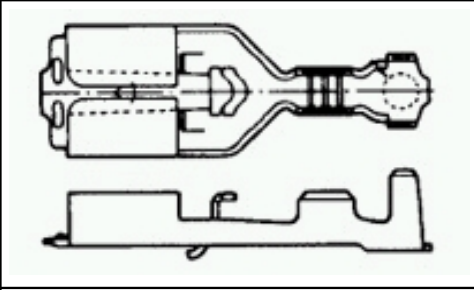

880646 -5

[Active](#)

Positive Lock Connectors

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Receptacle
- ? Tab Fit = 6.35 x 0.41 mm
- ? Line = Mark II
- ? Receptacle Style = Straight
- ? Wire Range = 0.50 - 1.00² [20-17] mm [AWG]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- ? [Positive Lock Receptacle](#) (PDF, English)

Catalog Pages/Data Sheets:

- ? None Available

Product Specifications:

- ? None Available

Application Specifications:

- ? None Available

Instruction Sheets:

- ? None Available

CAD Files:

- ? None Available

Additional Information:

- ? [Product Line Information](#)

Related Products:

- ? [Tooling](#)

[List all Documents](#)

Product Features

(Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Receptacle
- ? [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.41 [.250 x .016]
- ? [Receptacle Style](#) = Straight
- ? [Insulation Diameter \(mm \[in\]\)](#) = 2.00 - 3.30 [.079 -.130]
- ? [Material](#) = Brass
- ? [Finish](#) = Pre - Tin
- ? [Keyed](#) = No

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 0.50 - 1.00² [20-17]
- ? [Position Keyed](#) = None

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- ? [Packaging Method](#) = Strip

Other:

- ? [Line](#) = Mark II
- ? Brand = AMP