


928990-2 Product Details

 [Live Product Chat](#)

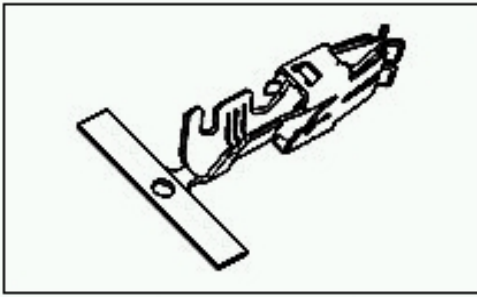


928990-2

TE Internal Number: 928990-2
✔ [Active](#)

 [View 3D PDF](#)

Timer Contacts

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Contact
- Contact Type = Standard Power-Timer
- Receptacle
- Wire Range = 0.20-0.60² [24-20] mm [AWG]
- Insulation Diameter = 1.00 - 1.60 mm

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

 [Add to My Part List](#)  [Request Sample](#)  [Find Similar Products](#)

Documentation & Additional Information

Product Drawings:

- [STANDARD POWER TIMER CONTACT \(PDF, German\)](#)

Catalog Pages/Data Sheets:

- [Automachine and General Products \(PDF, English\)](#)
- [TIMER STECKVERBINDER TIMER CCONNECTORS \(PDF, English\)](#)
- [Global Automotive Division Contact Systems \(1\) \(PDF, English\)](#)
- [Global Automotive Division Contact Systems \(2\) \(PDF, English\)](#)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing \(DXF, Version A10\)](#)
- [3D Model \(IGES, Version A10\)](#)
- [3D Model \(STEP, Version A10\)](#)

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Line Drawing](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Contact
- [Gender](#) = Receptacle
- [Insulation Diameter \(mm \[in\]\)](#) = 1.00 - 1.60 [0.039 - 0.063]
- [Tab Fit \(mm \[in\]\)](#) = 4.75 x 0.81 [.187 x .032]

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 0.20-0.60² [24-20]
- Single Wire Sealing System = No
- Insulation Type = FLR
- Cantilever Spring Material = Stainless Steel

Contact Related Features:

- [Contact Type](#) = Standard Power-Timer
- [Contact Material](#) = CuSn4
- [Contact Mating Area Plating Material](#) = Pre-Tin

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- [Terminate To](#) = Wire

Packaging Related Features:

- [Packaging Method](#) = Loose Piece

Other:

- GET 0.64 Connector System = No
- Brand = AMP