


963922 - 1 Product Details

Live Product Chat US Only
8:30am - 5pm ET, Mon - Fri

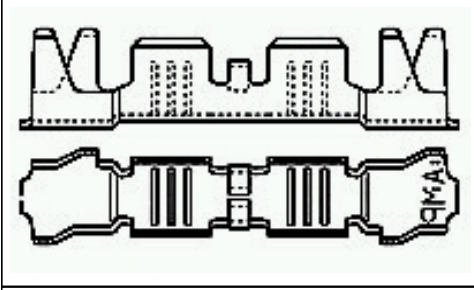

963922 - 1

[Active](#)

Splices - Open Barrel

[Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- ? Splice
- ? Insulation Support
- ? Wire/Cable Type = Regular Wire
- ? Wire Range = 1.00 - 2.50² [17-13.5] mm [AWG]
- ? Wire Range = 1970 - 4940 CMA

[View all Features](#) | [Find Similar Products](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

? None Available

Catalog Pages/Data Sheets:

? None Available

Product Specifications:

? None Available

Application Specifications:

? None Available

Instruction Sheets:

? None Available

CAD Files:

? None Available

Additional Information:

? [Product Line Information](#)

Related Products:

? [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- ? [Product Type](#) = Splice
- ? [Insulation Support](#) = Insulation Support
- ? [Wire/Cable Type](#) = Regular Wire
- ? [Insulation Diameter \(mm \[in\]\)](#) = 2.20 - 3.00 [.086 - .118]
- ? [Serrations](#) = With Serrations
- ? [Number of Serrations](#) = 6
- ? [Splicing Type](#) = Pigtail
- ? [Strip Type](#) = End Feed
- ? Material = Copper Alloy
- ? Finish = Pre - Tin

Body Related Features:

- ? [Wire Range \(mm \[AWG\]\)](#) = 1.00 - 2.50² [17-13.5]
- ? [Wire Range \(CMA\)](#) = 1,970 - 4,940
- ? [Stock Thickness \(mm \[in\]\)](#) = 0.33 [0.013]

Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Not relevant for lead free process
- ? RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

? Packaging Method = Strip

Other:

? Brand = AMP