




What can we help you find?



Home > Products > Parallel > Product Feature Selector > Product Details

352359-1 Product Details

Share | Print | Email

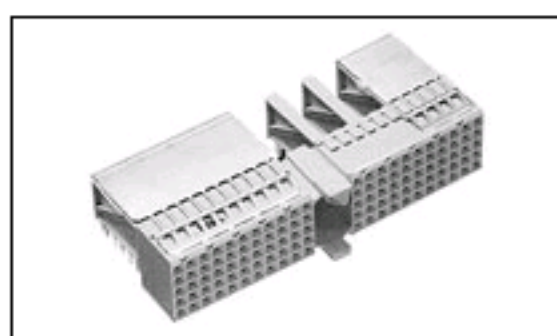

352359-1

TE Internal Number: 352359-1

Active

2mm Hard Metric PCB Mount Connectors (Z-PACK 2mm HM)

Always EU RoHS compliant but not ELV Compliant (Find RoHS Compliant Alternates/Statement of Compliance)

Product Highlights:

- Connector
- Connector Assembly
- Connector Style = Receptacle
- Type = Type A
- Interface Type = 2mm HM

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) | [Request Sample](#) | [Find Similar Products](#) | [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [Z-PACK 2MM HM TYPE A - 16 COLUMNS \(J4 VERSION\) PRE-S...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Connector
- Connector Type = Connector Assembly
- PCB Mounting Orientation = Right Angle

Mechanical Attachment:

- Board Mount = Free Board
- Front Mating Level = Level 1

Electrical Characteristics:

- Shielded = Yes

Termination Features:

- Interface Type = 2mm HM
- Termination End Plating = Tin-Lead over Nickel

Dimensions:

- Module Length (mm [in]) = 50.00 [1.968]

Body Features:

- Type = Type A
- CompactPCI Designation = J4 (Telephony)

Contact Features:

- Contact Configuration = Signal
- Feedthrough Post Length (mm [in]) = 3.30 [0.130]
- CompactPCI = Yes
- Contact Plating, Mating Area, Material = Performance-Based
- Grounding Contact = Without
- Contact Style = Feed through
- Number of Signal Contacts = 90
- Contact Base Material = Phosphor Bronze

Housing Features:

- Connector Style = Receptacle
- Mating Alignment = With
- Mating Alignment Type = Multi-Purpose Center
- Housing Color = Gray
- Housing Material = Polyester GF
- UL Flammability Rating = UL 94V-0

Configuration Features:

- Number of Rows = 5
- Number of Positions = 90
- Crosstalk Version = Standard
- Rows Loaded = D, C, B, A, E

Industry Standards:

- RoHS/ELV Compliance = RoHS/Not ELV Compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS not ELV compliant

Other:

- Brand = AMP
- Comment = Integrated Ground Return Upper shields.

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)

Quick Links

- [Check Distributor Inventory](#)
- [Cross Reference Products](#)
- [Find Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Search Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

