


[CONNECTORS](#)

# CONNECTOR HOUSINGS

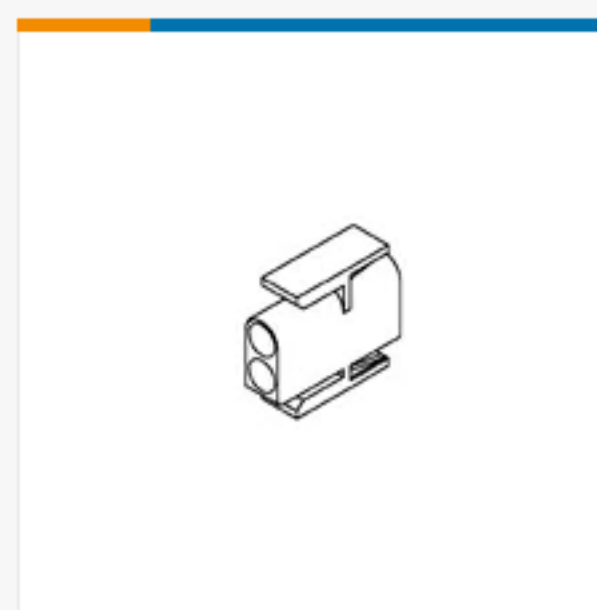

Active

[PRODUCT DRAWING](#)  
English

[3D MODEL](#)

[See All Documentation](#)

TE CONNECTIVITY

## 03P .140 MNL PLUG BLK HT

MATE-N-LOK | Commercial MATE-N-LOK

794060-1

TE Internal Number: 794060-1

Always EU RoHS/ELV Compliant

Centerline(mm) **6.1**

Number of Positions **3**

Housing Material **Nylon**

Connector Style **Plug**

Contact Type **Socket**

[See All Features](#)

North America

DISTRIBUTOR	QUANTITY	DATE AS OF
<b>DIGI-KEY CORPORATION</b> 800-344-4539	3,970	2015/08/18

- [GET SAMPLE](#)
- [SAVE TO LIST](#)
- [CHECK FOR TOOLING](#)
- [FIND SIMILAR PRODUCTS](#)

## DOCUMENTATION FEATURES

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features	Connector Style	<b>Plug</b>
	Product Type	<b>Connector</b>
	Connector Type	<b>Housing</b>
	Applies To	<b>Wire/Cable</b>
Configuration Features	Number of Positions	<b>3</b>
Electrical Characteristics	Voltage(VAC)	<b>250</b>
	Operating Voltage(VAC)	<b>250</b>
Body Features	Color	<b>Black</b>
Contact Features	Contact Type	<b>Socket</b>
	Contact Layout	<b>Inline</b>
Mechanical Attachment	Mounting Type	<b>Free Hanging</b>
Housing Features	Centerline(mm)	<b>6.1</b>
	Housing Material	<b>Nylon</b>
Dimensions	Length(mm)	<b>24.13</b>
	Height(mm)	<b>26.8</b>
	Width(mm)	<b>6.99</b>
Usage Conditions	Operating Temperature Range(°C)	<b>-55 – 105</b>
Operation/Application	For Use With	<b>Cap, Socket</b>
Industry Standards	UL Flammability Rating	<b>UL 94V-2</b>
Packaging Features	Packaging Quantity	<b>1</b>
	Packaging Method	<b>Package</b>
Product Compliance	<a href="#">Statement of Compliance</a> PDF	
	<a href="#">VIEW ALL PRODUCT COMPLIANCE</a>	

## COMPATIBLE

No compatible products found for 794060-1