


## Product Details for RSB3VP101201

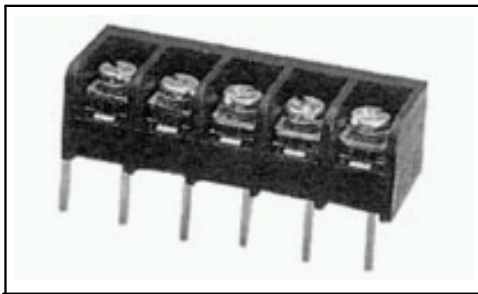

### RSB3VP101201

Tyco Part Number: 3 - 1437404 - 2

[Active](#)

### Barrier Strips, Barrier Strip Sockets

[RoHS Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- ? Barrier Strip
- ? Tri-Barrier Block Series
- ? Base Style = Flat
- ? 8.26 mm Centerline
- ? Number of Levels = Single

[View all Features](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

#### Product Drawings:

- ? None Available

#### Catalog Pages/Data Sheets:

- ? [TERMINAL BLOCKS](#) (PDF, English)

#### Product Specifications:

- ? None Available

#### Application Specifications:

- ? None Available

#### Instruction Sheets:

- ? None Available

#### CAD Files:

- ? None Available

#### Additional Information:

- ? [Product Line Information](#)

#### Related Products:

- ? [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- ? [Product Type](#) = Barrier Strip
- ? [Mount Angle](#) = Vertical
- ? [Mounting Ears](#) = Without
- ? [Number of Circuits](#) = 10
- ? [Screw Material](#) = Steel
- ? UL Recognized = File No. E60980

#### Mechanical Attachment:

- ? [Mounting Style](#) = Direct (All Positions Filled)
- ? [Screw Plating](#) = Bright Zinc/Chrome

#### Electrical Characteristics:

- ? [Base Style](#) = Flat
- ? [Number of Levels](#) = Single
- ? [End Barriers](#) = With
- ? [Mounting Insert](#) = Without
- ? [Top Hardware](#) = Steel Binding Combo Head Screws
- ? Bracket = Without

#### Body Related Features:

- ? [Block Series](#) = Tri -Barrier
- ? [Centerline \(mm \[in\]\)](#) = 8.26 [0.325]
- ? [Number of Rows](#) = 1
- ? [Terminal Style](#) = Printed Circuit Pin 5.08 [.200]
- ? CSA File No. = LR49571
- ? Wire Range (mm [AWG]) = 0.30 -3.00 <sup>2</sup> [22-12]

#### Industry Standards:

- ? [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- ? [Lead Free Solder Processes](#) = Wave solder capable to 240°C, Wave solder capable to 260°C, Wave solder capable to 265°C
- ? RoHS/ELV Compliance History = Always was RoHS compliant

#### Other:

- ? Brand = Buchanan