




Switches > Toggle Switches

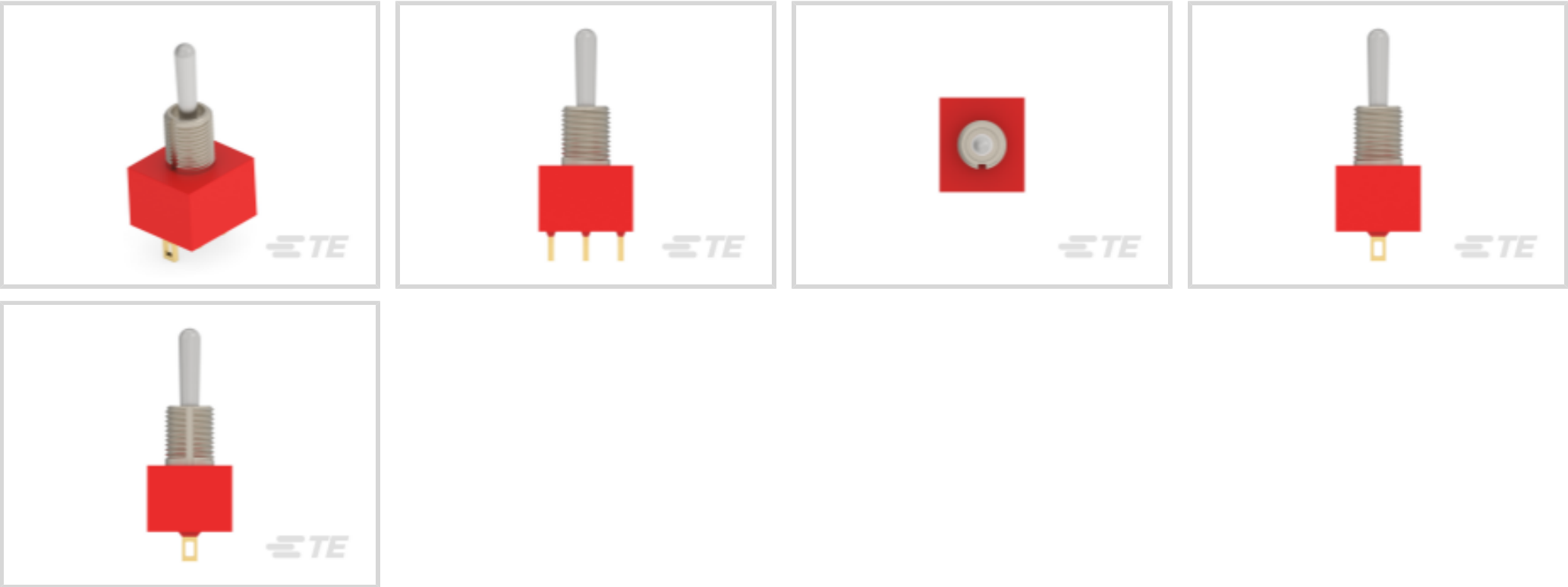

Configuration (Pole-Throw): **Double Pole - Double Throw**

Operating Function: **On On On**

Number of Positions: **3**

Contact Current Rating: **.4 A**

Operating Voltage: **20 VDC**

Features

Product Type Features

Sealed Device	Yes
Switch Connection Type	Wire Lugs
Toggle Style	Baton Long
Switch Type	Toggle Switch

Configuration Features

Configuration (Pole-Throw)	Double Pole - Double Throw
Operating Function	On On On
Number of Positions	3

Electrical Characteristics

Contact Resistance	10 mΩ
Insulation Resistance	1000 MΩ
Dielectric Withstanding Voltage (Max)	1000 VAC
Contact Current Rating	.4 A
Operating Voltage	20 VAC



Body Features

Actuator Finish	Nickel
Product Orientation	Horizontal
Bushing Style	Threaded
Bushing Thread Size	1/4-40

Contact Features

Contact Base Material	Copper
Switch Contact Plating Material	Gold

Mechanical Attachment

Product Mount Type	Panel Mount
--------------------	-------------

Housing Features

Process Sealed	No
----------------	----

Dimensions

	.35 in
Toggle Length	10.4 mm[.41 in]

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量超出标准 Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) SVHC > Threshold: Pb (3.7% in 4936246) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer



This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1825136-7
A101KZQ04



TE Part # 4-1825136-5
A101SYCQ04



TE Part # 4-1825136-9
A101SYZQ04




TE Part # 4-1825136-3
A101SYAQ04




TE Part # 5-1825136-9
A108P3ZQ04

Also in the Series | ALCOSWITCH Gemini A Series

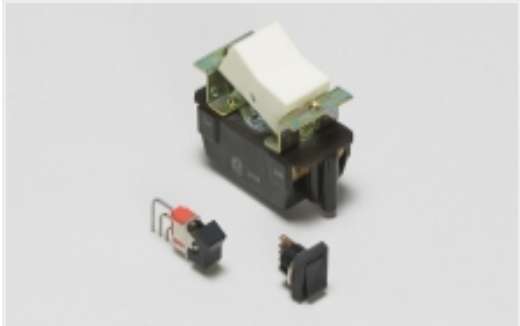

Rocker Switches(6)

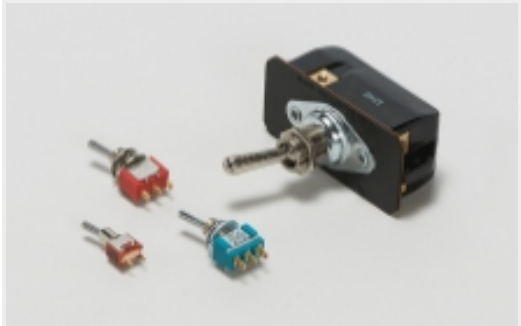

Toggle Switches(34)

Customers Also Bought





TE Part #GA10K3MCD1
MCD PROBE, 10K OHMS,+/- 0.2C @ 25C



TE Part #CSC-BNCM-1500-BNCM
BNC to BNC 1500mm RG58



TE Part #167024-1
MOD-4 REC.CONT.SCP.



TE Part #925366-2
MOD 4 REC.HSG 1X02P



TE Part #925366-3
MOD 4 REC.HSG 1X03P




TE Part #1622437-1
LR1 1% 330K



TE Part #6-1625890-9
2W SM M/OX 5% 820R



TE Part #2267078-8
TMD1T5B2M2RE

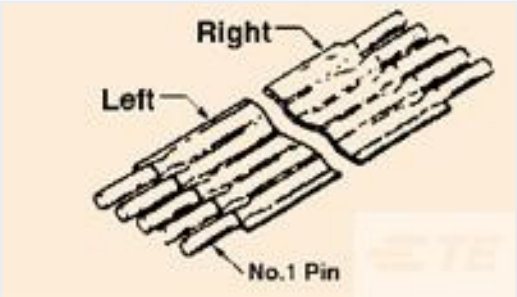

TE Part #9-6474612-2
FSN-22A-6



TE Part #6221-BCE-T-005-001
5KPA GAUGE SENSOR

Documents

Product Drawings

A211SYZB04

English

CAD Files

Customer View Model

ENG_CVM_CVM_3-1825139-8_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_3-1825139-8_A.3d_stp.zip

English

Customer View Model

ENG_CVM_CVM_3-1825139-8_A.2d_dxf.zip

English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



[SWITCHES_CORE_PROGRAM_CATALOG](#)

English

[GEMINI_SERIES_SWITCHES_QUICK_REF_GUIDE_2-1773458-5](#)

English