

Hart lock industrial grade 15A locking devices

Product description

2-pole, 3-wire grounding
15A, 250V/AC
NEMA L6-15



L6-15R



L6-15P

Industrial grade plugs & connectors



Rating A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	250	L6-15	Safety grip straight body	0.33-0.66" (8.4-16.7mm)	BK & W	□ CWL615P	□ CWL615C	•	•
			Auto grip straight body	0.33-0.66" (8.4-16.7mm)	BK & W	□ 6565N	□ 6566N	•	•

Industrial grade receptacles



Rating A	V/AC	NEMA	Description	Color	Single receptacle	Duplex receptacle		
15	250	L6-15	Standard industrial	BK	□ CWL615R	—	•	•
			Standard industrial	BK	—	□ 6580	•	•
			Isolated ground	RN	□ IGL615R*	—	•	•

*Not Fed Spec

Industrial grade flanged inlets & outlets



Rating A	V/AC	NEMA	Description	Color	Flanged inlet	Flanged outlet		
15	250	L6-15	Standard industrial	BK	□ CWL615FI	—	•	•
			Standard industrial	BK & W	—	□ CWL615FO*	•	•


*Only UL Listed & CSA certified, *Not Fed Spec



CWL615P



CWL615C

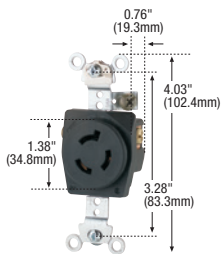

CWL615R



CWL615FI

Dimensional information:

C-76-C-78

Plug & connector specification information:

Safety grip K6-15: C-84
Auto grip K6-15: C-84

Receptacle specification information:

K6-15: C-86
Isolated ground K6-15: C-86

flanged inlet & flanged outlet specification information:

K6-15: C-88

Color information:

BK (Black), RN (Orange), W (White)



Compliances, specifications and availability are subject to change without notice.



Indicates NAFTA compliant - Page Q-30



RoHS compliant - Page Q-30