

Specification Grade Ground Fault Circuit Interrupter Receptacles

2-Pole, 3-Wire Grounding
15A, 125V/AC
20A, 125V/AC
NEMA 5-15, 5-20



5-15R



5-20R

Hospital Grade GFCIs

Back Wire & Side Wire	15A, 125V NEMA 5-15R				20A, 125V NEMA 5-20R			
Description	Catalog No. Color Suffix				Catalog No. Color Suffix			
Hospital GFCI	☐ VGFH15____ B, GY, LA, RD, V, W				☐ VGFH20____ B, GY, LA, RD, V, W			
Hospital GFCI NAFTA Compliant	☐ VGFH15F____ B, GY, LA, RD, V, W				☐ VGFH20F____ B, GY, LA, RD, V, W			
Tamper Resistant Hospital GFCI	☐ TRVGFH15____ B, GY, LA, RD, V, W				☐ TRVGFH20____ B, GY, LA, RD, V, W			
Tamper Resistant Hospital GFCI NAFTA Compliant	☐ TRVGFH15F____ B, GY, LA, RD, V, W				☐ TRVGFH20F____ B, GY, LA, RD, V, W			

Includes standard size unbreakable wallplate

Specification Grade GFCIs

Back Wire & Side Wire	15A, 125V NEMA 5-15R				20A, 125V NEMA 5-20R			
Description	Catalog No. Color Suffix				Catalog No. Color Suffix			
Duplex GFCI	☐ VGF15____ A, B, BK, GY, LA, RD, V, W				☐ VGF20____ A, B, BK, GY, LA, RD, V, W			
Duplex GFCI with Mid-Size Wallplate	☐ VGF15____-M A, LA, V, W							
Duplex GFCI NAFTA Compliant	☐ VGF15F____ B, BK, GY, LA, RD, V, W				☐ VGF20F____ B, BK, GY, LA, RD, V, W			
Tamper Resistant Duplex GFCI	☐ TRVGF15____ A, B, BK, GY, LA, RD, V, W				☐ TRVGF20____ A, B, BK, GY, LA, RD, V, W			
Tamper Resistant Duplex GFCI with Mid-Size Wallplate	☐ TRVGF15____-M A, LA, V, W							
Tamper Resistant Duplex GFCI NAFTA Compliant	☐ TRVGF15F____ B, BK, GY, LA, RD, V, W				☐ TRVGF20F____ B, BK, GY, LA, RD, V, W			
Weather Resistant Duplex GFCI	☐ WRVGF15____ B, GY, V, W				☐ WRVGF20____ B, GY, V, W			
Tamper & Weather Resistant Duplex GFCI	☐ TWRVGF15____ B, GY, LA, V, W				☐ TWRVGF20____ B, GY, LA, V, W			

Includes standard size unbreakable wallplate unless otherwise noted
Consult factory customer service representative for additional packaging options

Color Ordering Information

For ordering devices, include Cat. No. followed by the color code: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), RD (Red), RN (Orange), V (Ivory), W (White)

Icon Key

ArrowLink™ option available. Add "MOD" suffix to Standard catalog number (example VGF15W, VGF15WMOD). For ordering information on ArrowLink & ArrowLink SPD connectors, see page G-2.

Hospital Grade



Build-To-Spec Customizable Devices - see page G-1



NAFTA Compliant - see page O-30




Tamper Resistant




Weather Resistant




Tamper & Weather Resistant

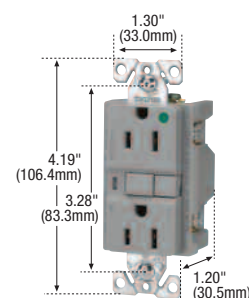


VGFH15

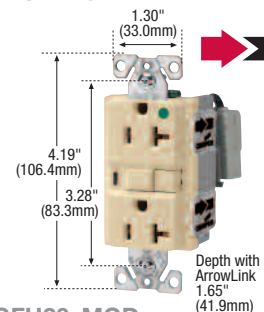


VGFH20_MOD

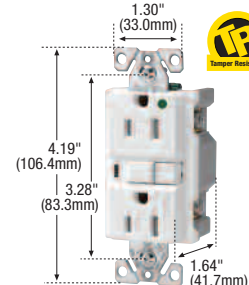

TRVGFH15

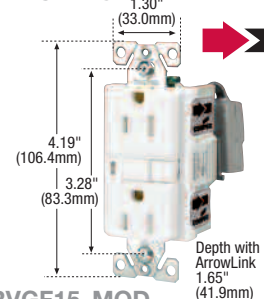

TRVGF15_MOD

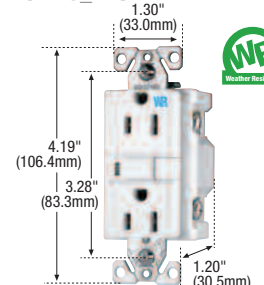

WRVGF15

Specification Information:

Hospital Grade GFCI: G-12

Spec Grade GFCI: G-13